


# EA615BC-20-44 両口スパナ

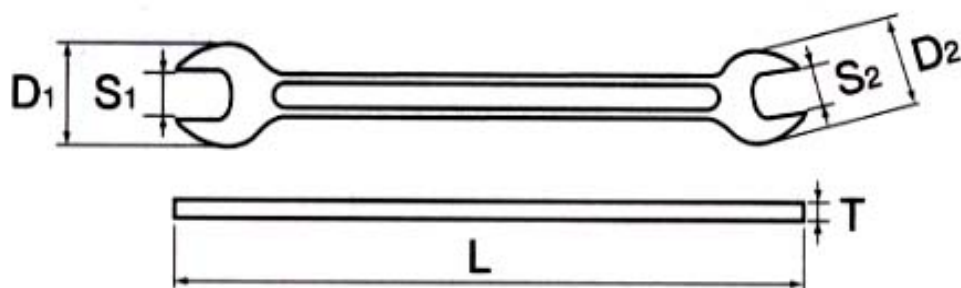

	S1 × S2	D1	D2	T	L	▼ g
BC - 20	5.5 × 7	12	15	3.5	102	15
BC - 21	6 × 7	13	15	3.5	102	15
BC - 22	6 × 8	13	17	4	107	18
BC - 23	7 × 8	15	17	4	112	20
BC - 24	8 × 9	17	19	4.5	118	30
BC - 25	8 × 10	17	21	4.5	122	40
BC - 26	10 × 11	21	23	5	133	45
BC - 27	10 × 12	21	25	5.5	138	60
BC - 28	10 × 13	21	27	6	143	60
BC - 29	11 × 13	23	27	6	148	65
BC - 30	12 × 14	25	29	6.5	158	75
BC - 31	13 × 17	27	36	7	167	100
BC - 32	14 × 17	29	36	7	173	105
BC - 33	17 × 19	36	40	7.5	195	145
BC - 34	17 × 21	36	44	8	203	170
BC - 35	19 × 21	40	44	8	218	195
BC - 36	19 × 22	40	46	8.5	223	205
BC - 37	21 × 23	44	48	8.5	233	240
BC - 38	21 × 26	44	54	8.5	238	260
BC - 39	22 × 24	46	50	9	244	260
BC - 40	23 × 26	48	54	9	248	300
BC - 41	24 × 27	50	55	9	253	320
BC - 42	26 × 32	54	65	10.5	273	460
BC - 43	27 × 30	56	61	10	273	430
BC - 44	30 × 32	62	65	10.5	294	525

(単位mm)