 



# EA615KA-1~-44

(両口スパナ)

○ クロム合金鋼

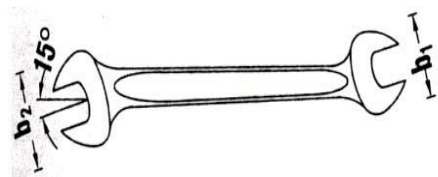

EA品番	対辺	L	b1	b2	a	重量(g)
KA-1	4X5	100	12.5	14	3.4	11
KA-3	5.5X7	120	14.8	17	3.7	19
KA-4	6X7	120	15.5	17	3.7	17
KA-5	7X8	140	17	18	4	25
KA-6	8X9	140	18	21	4	21
KA-7	8X10	140	18	23	4.5	33
KA-8	10X11	155	23	26	4.8	48
KA-9	10X12	170	23	28	5.3	51
KA-10	10X13	170	23	30	5.3	57
KA-10B	11X13	170	26	30	5.3	55
KA-11	12X13	170	28	30	5.3	64
KA-12	12X14	170	28	32	5.3	63
KA-13	13X14	190	30	32	5.3	70
KA-13B	13X15	190	30	35	5.3	73
KA-14	13X17	205	30	38	5.8	92
KA-15	14X15	190	32	35	5.3	81
KA-16	14X17	205	32	38	5.8	99
KA-19	16X17	205	36	38	5.8	100
KA-19B	16X18	220	36	40	6.7	125
KA-20	17X19	220	38	42	6.7	131
KA-22	18X19	220	40	42.5	6.7	147
KA-23	19X22	235	42	49	7.3	179
KA-26	20X22	235	45	49	7.3	185
KA-28	21X23	250	47	51	7.8	225
KA-28B	21X24	250	47	53	7.8	215
KA-29	22X24	250	49	53	7.8	232
KA-31	24X26	270	53	57.5	8.3	293
KA-32	24X27	280	53	60	8.3	299
KA-34	25X28	285	55	62	8.3	309
KA-35	27X30	300	60	66	9.4	412
KA-36	27X32	300	60	70	9.4	418
KA-37	30X32	300	66	70	9.4	451
KA-38	30X34	300	66	75	9.4	480
KA-41	32X36	325	70	80	10	546
KA-42	34X36	325	75	80	10	619
KA-43	36X41	375	80	88	11	800
KA-44	41X46	425	88	94.5	12	1040

(単位mm)