


EA616B-1-19メガネレンチ

45° × 6°

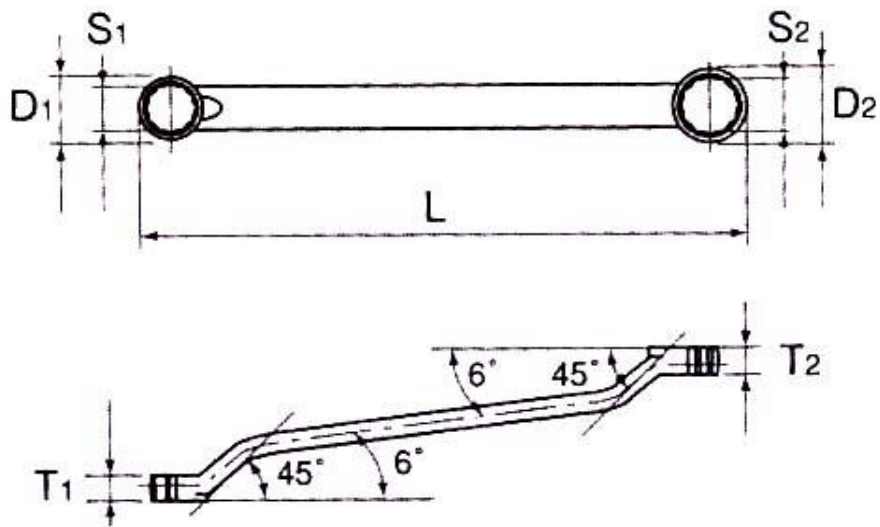

	S1 × S2	D1	D2	T1	L	▼ g
EA616B-1	5.5 × 7	9	11	2.8	151	20
EA616B-2	6 × 7	10	11	2.8	151	20
EA616B-3	8 × 9	12	14	3.5	173	40
EA616B-4	8 × 10	12	15	3.5	179	45
EA616B-5	10 × 12	15	18	3.9	207	70
EA616B-6	10 × 13	15	19	3.9	207	70
EA616B-7	10 × 14	15	20	4.2	218	82
EA616B-8	11 × 13	17	19	4.2	218	80
EA616B-9	12 × 14	18	20	4.4	225	100
EA616B-10	13 × 17	19	25	5	252	135
EA616B-11	14 × 17	20	25	5	253	140
EA616B-12	17 × 19	25	27	5.8	286	220
EA616B-13	17 × 21	25	30	6	308	250
EA616B-14	19 × 21	27	30	6.2	309	270
EA616B-15	19 × 22	27	32	6.2	320	280
EA616B-16	21 × 23	30	33	6.6	322	335
EA616B-17	22 × 24	32	35	7	334	380
EA616B-18	23 × 26	33	37	7.2	356	410
EA616B-19	24 × 27	35	38	7.4	367	440