


# EA617WC-19-60 (3/4")ソケット

## 1. 特長

- ・ 6ポイント
- ・ クロム合金鋼、クロムメッキ仕上げ

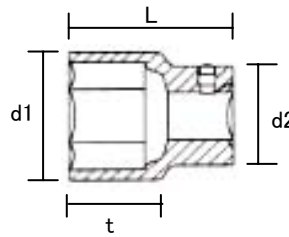

## 2. サイズ

品番	対辺(mm)	d1(mm)	d2(mm)	L(mm)	t(mm)	重量(g)	
<del>EA617WC-19</del>	<del>19</del>	<del>28.5</del>	<del>38</del>	<del>50</del>	<del>25</del>	<del>218</del>	廃盤
EA617WC-21	21	31	38	50	25	226	
EA617WC-22	22	32	38	52	27	244	
<del>EA617WC-23</del>	<del>23</del>	<del>33.5</del>	<del>38</del>	<del>52</del>	<del>27</del>	<del>248</del>	廃盤
EA617WC-24	24	34.5	38	52	27	254	
EA617WC-27	27	38.5	38	55	30	280	
<del>EA617WC-28</del>	<del>28</del>	<del>39.5</del>	<del>38</del>	<del>57</del>	<del>32</del>	<del>298</del>	廃盤
<del>EA617WC-29</del>	<del>29</del>	<del>41</del>	<del>38</del>	<del>57</del>	<del>32</del>	<del>303</del>	廃盤
EA617WC-30	30	42	38	58	33	313	
EA617WC-32	32	44.5	38	58	33	332	
EA617WC-33	33	46	38	60	35	355	
<del>EA617WC-34</del>	<del>34</del>	<del>47</del>	<del>40</del>	<del>60</del>	<del>35</del>	<del>381</del>	廃盤
EA617WC-36	36	49.5	40	60	35	399	
EA617WC-38	38	52	40	64	39	437	
EA617WC-41	41	55.5	40	67	42	497	
EA617WC-46	46	61	40	73	48	615	
EA617WC-50	50	66	40	80	55	769	
EA617WC-55	55	72	40	80	55	954	
<del>EA617WC-60</del>	<del>60</del>	<del>78</del>	<del>40</del>	<del>80</del>	<del>55</del>	<del>1023</del>	廃盤