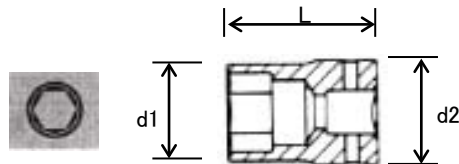


## EA617XC-3.2-14 (1/4")ソケット

### 1. 特長

 

- ・ 6ポイント
- ・ クロム合金鋼、クロムメッキ仕上げ



### 2. サイズ

	品番	対辺(mm)	d1(mm)	d2(mm)	L(mm)	重量(g)
廃番	EA617XC-3.2	3.2	5.6	11	23	8
廃番	EA617XC-3.5	3.5	6	11	23	8
廃番	EA617XC-4	4	6.7	11	23	9
廃番	EA617XC-4.5	4.5	7.3	11	23	9
	EA617XC-5	5	7.9	11	23	8
	EA617XC-5.5	5.5	8.5	11	23	9
	EA617XC-6	6	9.2	11	23	9
	EA617XC-7	7	11	11	23	10
	EA617XC-8	8	12	12	23	12
	EA617XC-9	9	13	13	23	14
	EA617XC-10	10	14.5	14.5	23	18
	EA617XC-11	11	15.5	15.5	23	20
	EA617XC-12	12	17	17	23	24
	EA617XC-13	13	18	18	23	28
	EA617XC-14	14	19.5	19.5	24	32

### Sockets

		d1	d2	L	
	"	mm	mm	mm	g
	3.2	5.6	11	23	8
	3.5	6	11	23	8
	4	6.7	11	23	9
	4.5	7.3	11	23	9
	5	7.9	11	23	8
	5.5	8.5	11	23	9
	6	9.2	11	23	9
	7	11	11	23	10
	8	12	12	23	12
	9	13	13	23	14
	10	14.5	14.5	23	18
	11	15.5	15.5	23	20
	12	17	17	23	24
	13	18	18	23	28
	14	19.5	19.5	24	32

DIN 3124/ISO 2725,  
hexagon,  
chrome alloy steel, chrome