


EA617YA-7-24 (3/8")ソケット

1.特長

- ・12ポイント
- ・クロム合金鋼、クロムメッキ仕上げ

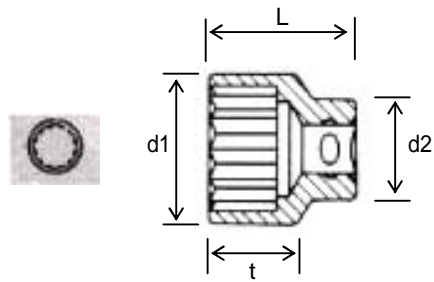

2.サイズ

品番	対辺 (mm)	d1 (mm)	d2 (mm)	L (mm)	t (mm)	重量 (g)
EA617YA-7	7	10.5	16.5	24	12.5	19
EA617YA-8	8	11.7	16.5	25	13.5	19
EA617YA-9	9	13	16.5	25	13.5	19
EA617YA-10	10	14.3	16.5	27	15.5	20
EA617YA-11	11	15.6	16.5	27	13.7	21
EA617YA-12	12	16.9	17.5	28	14.4	24
EA617YA-13	13	18	17.5	30	16.1	25
EA617YA-14	14	19.4	17.5	30	15.8	28
EA617YA-15	15	20.6	19	31	19.2	30
EA617YA-16	16	21.7	19	31	18.9	33
EA617YA-17	17	23	19	31	18.6	37
EA617YA-18	18	24.2	19	32	19.3	39
EA617YA-19	19	25.2	19	32	19	39
EA617YA-20	20	26.2	20	34	20.7	51
EA617YA-21	21	27.7	21	34	20.5	53
EA617YA-22	22	28.7	21	35	21.2	61
EA617YA-24	24	31.5	24	35	21.2	92