


EA617YB - 1 - 14 (3/8")ソケット

1.特長

- ・12ポイント
- ・クロム合金鋼、クロムメッキ仕上げ

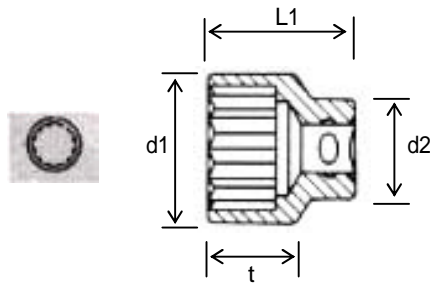

2.サイズ

品番	対辺 (")	d1 (mm)	d2 (mm)	L (mm)	t (mm)	重量 (g)
EA617YB-1	1/4	9.7	16.5	24	12.5	18
EA617YB-2	5/16	11.7	16.5	25	13.5	19
EA617YB-3	11/32	12.5	16.5	25	13.5	19
EA617YB-4	3/8	13.7	16.5	27	15.5	20
EA617YB-5	7/16	15.8	16.5	28	15.1	20
EA617YB-6	1/2	18	17.5	30	16.5	24
EA617YB-7	9/16	20.2	19	31	16.8	28
EA617YB-7A	19/32	20.6	19	31	19.2	36
EA617YB-8	5/8	21.7	19	31	18.9	31
EA617YB-9	11/15	23.4	19	32	19.5	34
EA617YB-10	3/4	25.2	19	32	19	41
EA617YB-11	13/16	27.2	20.5	34	20.5	52
EA617YB-12	7/8	28.7	22	35	21	59
EA617YB-13	15/16	31.5	24	35	20.7	95
EA617YB-14	1	33	25.5	35	20.2	97