


## EA617YC-7-22 (3/4")ソケット

### 1. 特長

- ・ 6ポイント
- ・ クロム合金鋼、クロムメッキ仕上げ

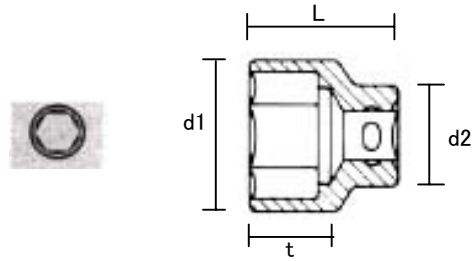

### 2. サイズ

品番	対辺(mm)	d1(mm)	d2(mm)	L(mm)	t(mm)	重量(g)
EA617YC-7	7	10.5	17	23	11	19
EA617YC-8	8	11.7	17	23	11	20
EA617YC-9	9	13	17	23	11	19
EA617YC-10	10	14.3	17	23	11	20
EA617YC-11	11	15.6	17	23	11	21
EA617YC-12	12	16.9	17.5	24	12	24
EA617YC-13	13	18.1	17.5	24	12	25
EA617YC-14	14	19.4	18	25	13	30
EA617YC-15	15	20.6	18	25	13	31
EA617YC-16	16	21.8	18	26	14	33
EA617YC-17	17	23	18	26	14	36
EA617YC-18	18	24.2	18.5	27	15	40
EA617YC-19	19	25.5	18	28	16	43
EA617YC-20	20	26.7	20.5	28	16	53
EA617YC-21	21	28	21.8	28	16	57
EA617YC-22	22	29.2	21	29	17	62