


EA617ZF-1~10
 (1/2"ディープ ソケット)

- クロム合金鋼
- 12ポイント
- 差込角 1/2"

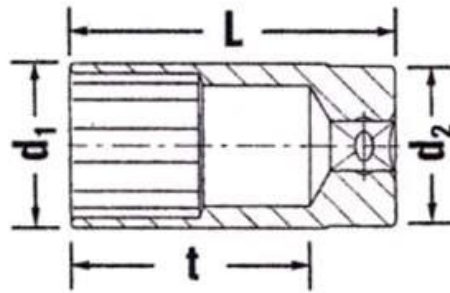

| | 対辺 | d1 | d2 | L | t | 重量(g) |
|-------|---------|------|------|----|------|-------|
| ZF-1 | 1/2" | 18.3 | 23 | 83 | 66 | 122 |
| ZF-2 | 9/16" | 20.3 | 23 | 83 | 66 | 131 |
| ZF-3 | 5/8" | 22.3 | 23.5 | 83 | 65.5 | 145 |
| ZF-4 | 11/16" | 24.3 | 23 | 83 | 65 | 158 |
| ZF-5 | 3/4" | 26.3 | 25 | 83 | 65 | 188 |
| ZF-6 | 7/8" | 30.1 | 29 | 83 | 64 | 246 |
| ZF-7 | 15/16" | 32.1 | 31 | 83 | 63.5 | 281 |
| ZF-8 | 1" | 34.1 | 33 | 83 | 63 | 312 |
| ZF-9 | 1 1/16" | 36.1 | 35 | 83 | 63 | 359 |
| ZF-10 | 1 1/8" | 38.1 | 37.2 | 83 | 62.5 | 391 |

(単位mm)