


| 2300M<br>2305M<br>(mm) | D <sub>1</sub><br>(mm) | D <sub>2</sub><br>(mm) | H <sub>1</sub><br>(mm) | H <sub>2</sub><br>(mm) | L<br>(mm) | 重量<br>(g) | 包装個数<br>(pcs.) |
|------------------------|------------------------|------------------------|------------------------|------------------------|-----------|-----------|----------------|
| 3                      | 5.5                    | 11.2                   | 3                      | 40                     | 50        | 15        | 10             |
| 4                      | 6.7                    | 11.2                   | 4                      | 40                     | 50        | 15        | 10             |
| 4.5                    | 7.3                    | 11.2                   | 4.5                    | 40                     | 50        | 15        | 10             |
| 5                      | 8                      | 11.2                   | 5.5                    | 40                     | 50        | 17        | 10             |
| 5.5                    | 8.5                    | 11.2                   | 6                      | 40                     | 50        | 17        | 10             |
| 6                      | 9.2                    | 11.2                   | 7                      | 40                     | 50        | 20        | 10             |
| 7                      | 10.5                   | 11.2                   | 8                      | 40                     | 50        | 25        | 10             |
| 8                      | 11.8                   | 11.2                   | 9                      | 40                     | 50        | 25        | 10             |
| 9                      | 13                     | 12                     | 10                     | 40                     | 50        | 30        | 10             |
| 10                     | 14.3                   | 12.9                   | 11                     | 39                     | 50        | 34        | 10             |
| 11                     | 15.5                   | 14.3                   | 12                     | 39                     | 50        | 43        | 10             |
| 12                     | 16.8                   | 15.5                   | 13                     | 39                     | 50        | 50        | 10             |
| 13                     | 18                     | 16.4                   | 14                     | 39                     | 50        | 52        | 10             |
| 14                     | 19.3                   | 17.9                   | 16                     | 38                     | 50        | 57        | 10             |

| RS2300M/12                                | 12ヶ組/レール200mm | 重量<br>(g) | 希望小売<br>価格 |
|-------------------------------------------|---------------|-----------|------------|
| 4, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13, 14 |               | 400       | ¥ 16,900   |

**2300M**  
(ミリサイズ)

○ 六角ディープソケット

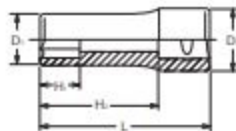

**RS2300M/12**  
(ミリサイズ)



六角ディープソケット



レールセット



EA618AF-1