


EA618AH-101~110
 (1/4" ディープソケット)

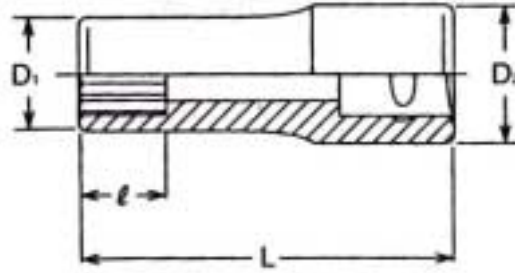

- 差込角 1/4"
- 12ポイント

	対辺	D1	D2	ℓ	L	重量(g)
AH-101	1/8"	5.4	12	4	50	17
AH-102	3/16"	8	12	6	50	20
AH-103	1/4"	19.8	12	7	50	25
AH-104	9/32"	10.9	12	8	50	25
AH-105	5/16"	11.6	12	9	50	29
AH-106	11/32"	13	12	10	50	30
AH-107	3/8"	14.3	12.8	11	50	34
AH-108	7/16"	16	14.2	12	50	43
AH-109	1/2"	18	16.2	14	50	50
AH-110	9/16"	19	17.1	16	50	55

(mm)