


EA618BV-5~-24
(3/8" ソケット)

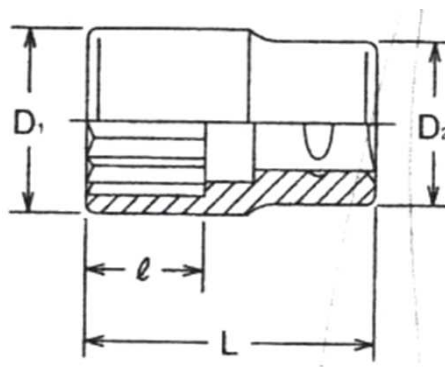

- 差込角 3/8"
- 12ポイント

	対辺	D1	D2	ℓ	L	重量(g)
廃番 EA618BV-5	5	8.3	17.3	5	26	20
廃番 EA618BV-5.5	5.5	8.9	17.3	5.5	26	20
廃番 EA618BV-6	6	9.9	17.3	6	26	20
EA618BV-7	7	10.8	17.3	6.5	26	20
EA618BV-8	8	12	17.3	7	26	22
EA618BV-9	9	13.3	17.3	7.5	26	23
EA618BV-10	10	14.5	17.3	8	26	24
EA618BV-11	11	15.8	17.3	8.5	26	25
EA618BV-12	12	16.8	17.3	9	26	25
EA618BV-13	13	18	17	9.5	26	24
EA618BV-14	14	19.5	18.5	11	27	31
EA618BV-15	15	20.8	19.5	11.5	28	39
EA618BV-16	16	22	20	12	28	42
EA618BV-17	17	23.3	21.5	12.5	29	51
EA618BV-18	18	24.5	22.5	13	30	51
EA618BV-19	19	25.8	23.5	13.5	30	63
EA618BV-20	20	27	24.5	14	31	75
EA618BV-21	21	28	26	14.5	32	77
EA618BV-22	22	29.5	26.5	15	32	82
EA618BV-23	23	30.8	27.5	15.5	33	95
EA618BV-24	24	32	28.5	16	34	102

(mm)