


EA618CG-1 ~ -18 (1/2")ソケット

12角ソケット
差込角 1/2"

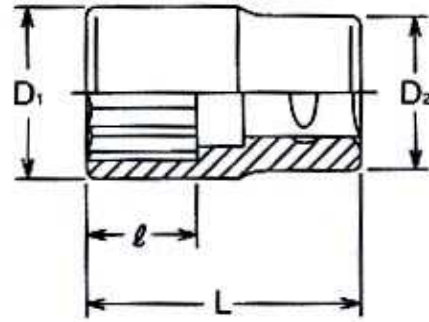

廃番	サイズ(mm)	D1(mm)	D2(mm)	l (mm)	L (mm)	重量(g)
EA618CG-1	5/16	13.2	21	8	36	44
EA618CG-2	3/8	14.6	21	9	37	44.5
EA618CG-3	7/16	16.5	21	9.5	37	46
EA618CG-4	1/2	19	22	10.5	37	53
EA618CG-5	9/16	20.3	22	11	37	56
EA618CG-6	5/8	22.8	22	12	37	62
EA618CG-7	11/16	25	24	13	37	74
EA618CG-8	3/4	26.5	25	14	38	89
EA618CG-9	13/16	29	27	15.5	38	102
EA618CG-10	7/8	30	28	16	40	113
EA618CG-11	15/16	32.8	30	17	42	140
EA618CG-12	1	35	32	19	42	165
EA618CG-13	1-1/16	36.5	33	19.5	43	196
EA618CG-14	1-1/8	39	35	20.5	43	190
EA618CG-15	1-3/16	40	36	22	46	222
EA618CG-16	1-1/4	42.8	38	23	46	250
EA618CG-17	1-3/8	46.2	40	24	47	317
EA618CG-18	1-1/2	49.2	43	24	47	380