


EA618CT - 104 ~ - 119
 (1/2" インヘックスビットソケット)

差込角 1/2"

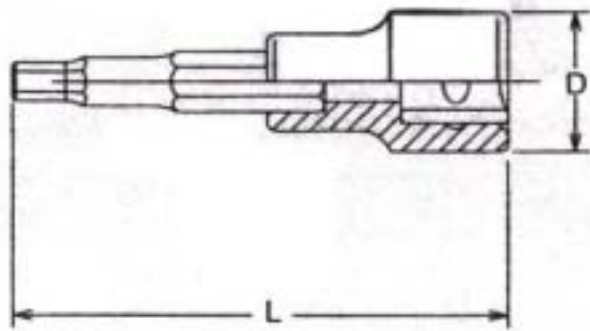

	対辺	D	L	重量(g)
CT - 104	4	22	100	77
CT - 105	5	22	100	78
CT - 106	6	22	100	80
CT - 107	7	22	100	82
CT - 108	8	22	100	84
CT - 110	10	22	100	109
CT - 112	12	23	100	155
CT - 114	14	24	100	180
CT - 117	17	24	100	210
CT - 119	19	26	100	260

(mm)