


EA618DE-17~-65
(3/4" ソケット)

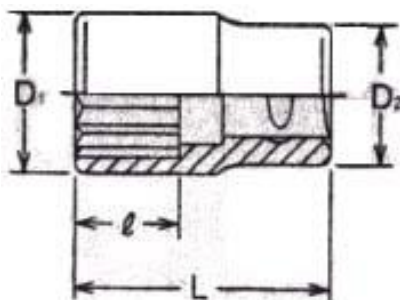

- 差込角 3/4"
- 12ポイント

	対辺	D1	D2	ℓ	L	重量(g)
DE-17	17	26	34	12.5	50	176
DE-18	18	27	34	13	50	178
DE-19	19	28.5	34	13.5	50	179
取扱中止 DE-20	20	29.5	34	14	50	185
DE-21	21	31	34	14.5	50	185
DE-22	22	32	34	15	50	187
DE-23	23	33.5	34	16	50	187
DE-24	24	34.5	34	17	50	200
取扱中止 DE-25	25	36	34	17.5	50	217
DE-26	26	37	34	18	50	222
DE-27	27	38.5	34	19	53	254
DE-28	28	39.5	37	19.5	53	298
DE-29	29	41	38	20	53	292
DE-30	30	42	38	21	55	301
DE-31	31	43.5	38	22	55	294
DE-32	32	44.5	38	23	57	351
DE-33	33	46	40	23.5	57	384
DE-34	34	47	40	24	57	397
DE-35	35	48.5	40	24.5	57	422
DE-36	36	49.5	42	25	59	438
DE-37	37	51	42	25.5	59	484
DE-38	38	52	42	26	59	523
DE-39	39	53.5	45	26.5	59	538
DE-40	40	54.5	45	27	59	550
DE-41	41	56	47	28	62	633
DE-42	42	57	47	28.5	62	652
DE-43	43	58.5	47	29	62	659
DE-44	44	59.5	47	29.5	62	657
DE-45	45	61	47	30	62	734
DE-46	46	62	47	31	68	791
DE-47	47	63.5	47	31.5	68	816
DE-48	48	64.5	50	32	68	892
DE-50	50	67	48	34	68	949
DE-52	52	69.5	53	33	72	925
DE-54	54	72	55	33	72	1040
DE-55	55	73.5	53	36	72	1006
DE-56	56	74.5	53	36	72	1092
DE-57	57	76	53	36	72	1169
DE-58	58	77	53	36	72	1149
DE-60	60	79.5	58	39	76	1420
DE-63	63	83.5	58	39	76	1497
DE-65	65	86	63	42	80	1608

(mm)