


EA618DF-1~33
(3/4" ソケット)

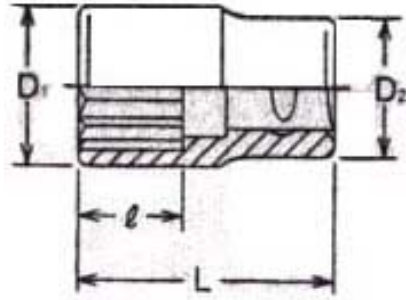

- 差込角 3/4"
- 12ポイント

	対辺	D1	D2	φ	L	重量(g)
DF-1	11/16"	27	34	13	50	178
DF-2	3/4"	28.5	34	13.5	50	179
DF-3	25/32"	29.5	34	14	50	185
DF-4	13/16"	31	34	14.5	50	185
DF-5	7/8"	32	34	15	50	187
DF-6	15/16"	34.5	34	17	50	200
DF-7	31/32"	36	34	17.5	50	217
DF-8	1"	37	34	18	50	222
DF-9	1 1/16"	38.5	37	19.5	53	298
DF-10	1 1/8"	41	38	20	53	292
DF-11	1 3/16"	42	38	21	55	301
DF-12	1 1/4"	44.5	40	23	57	351
DF-13	1 5/16"	46	40	23.5	57	384
DF-14	1 3/8"	48.5	42	24.5	57	422
DF-15	1 7/16"	51	42	25.5	59	484
DF-16	1 1/2"	52	45	26	59	523
DF-17	1 9/16"	54.5	45	27	59	550
DF-18	1 5/8"	56	47	28	62	633
DF-19	1 11/16"	58.5	47	29	62	659
DF-20	1 3/4"	59.5	47	29.5	62	657
DF-21	1 13/16"	62	47	31	68	791
DF-22	1 7/8"	64.5	50	32	68	892
DF-23	1 15/16"	66	48	32.5	68	928
DF-24	2"	68.5	52	34.5	68	949
DF-25	2 1/16"	71	54	33	72	983
DF-26	2 1/8"	72	55	33	72	1040
DF-27	2 3/16"	74.5	53	36	72	1092
DF-28	2 1/4"	76	53	36	72	1169
DF-29	2 5/16"	78.5	53	36	72	1344
DF-30	2 3/8"	79.5	58	39	76	1402
DF-31	2 7/16"	82	58	39	76	1420
DF-32	2 1/2"	84.5	58	39	76	1497
DF-33	2 9/16"	86	63	42	80	1608

(mm)