


EA618ED - 35 ~ - 100
(1" ソケット)

差込角 1"
12ポイント

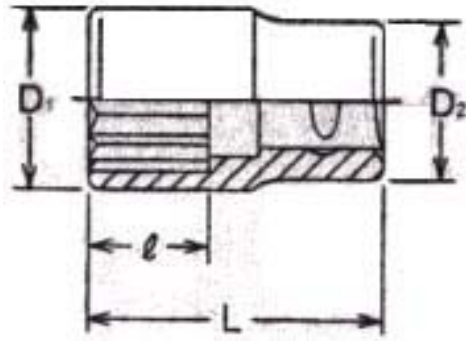

	対辺	D 1	D 2	l	L	重量(g)
ED - 35	35	50.5	48	24.5	65	536
ED - 36	36	51.5	48	25	65	600
ED - 38	38	54	50	26	65	624
ED - 40	40	56.5	53	27	65	686
ED - 41	41	58	53	28	68	747
ED - 42	42	59	53	28.5	68	789
ED - 46	46	64	53	31	72	928
ED - 50	50	69	53	34	72	943
ED - 54	54	74	54	37	72	1027
ED - 55	55	75.5	55	37	72	1016
ED - 58	58	79	53	41	77	1200
ED - 60	60	81.5	58	46	82	1440
ED - 63	63	85.5	58	45	82	1470
ED - 65	65	88	63	45	86	1683
ED - 67	67	90.5	63	49	86	1840
ED - 68	68	91.5	63	49	86	1800
ED - 70	70	94	68	50	88	1963
ED - 71	71	95.5	68	50	88	2200
ED - 75	75	100.5	73	53	90	2204
ED - 80	80	106.5	75	58	95	2550
ED - 83	83	110.5	78	57	95	2730
ED - 85	85	113	80	57	95	2680
ED - 90	90	119	80	59	100	3420
ED - 95	95	125.5	85	58	100	4900
ED - 100	100	131.5	85	57	100	4840

(mm)