


T B T形ボックスレンチ

T-Handled Wrench

Code	mm	D mm	T mm	L ₁ mm	L ₂ mm	d mm	重量 g	箱入数	
TB0006	6	10	11	110	100	8	80	-	EA618GJ-6
TB0007	7	12	11	110	100	8	85	-	EA618GJ-7
TB0008	8	13	11	110	100	8	85	-	EA618GJ-8
TB0009	9	14	11	110	100	8	90	-	EA618GJ-9
TB0010	10	15.5	13	150	135	8	120	10	EA618GJ-10
TB0011	11	17	15	150	135	10	195	10	EA618GJ-11
TB0012	12	18	16	160	160	10	210	10	EA618GJ-12
TB0013	13	19	17	160	160	10	210	10	EA618GJ-13
TB0014	14	21	18	160	160	10	227	10	EA618GJ-14
TB0017	17	24.5	20	180	180	11	295	10	EA618GJ-17
TB0019	19	28	24	200	190	13	440	10	EA618GJ-19
TB0021	21	30	25	210	200	13	465	10	EA618GJ-21
TB0022	22	32	27	210	200	13	510	5	EA618GJ-22
TB0024	24	34	29	235	220	14	650	5	EA618GJ-24
TB0026	26	38	32	250	240	16	860	5	EA618GJ-26
TB0027	27	38	33	250	240	16	850	-	EA618GJ-27
TB0030	30	44	37	265	250	19	1,225	-	EA618GJ-30
TB0032	32	44	39	270	250	19	1,300	-	EA618GJ-32
TB0036	36	50	44	290	280	22	1,810	-	EA618GJ-36
TB0041	41	58	45	310	300	25	2,800	-	EA618GJ-41
TB0046	46	61	46	320	340	28	2,860	-	EA618GJ-46
TB0050	50	66	56	360	380	28	3,420	-	EA618GJ-50
TB0055	55	73	60	380	400	28	4,420	-	



- ・ニッケルクロムメッキ (41mm 以下のサイズ)
- ・カチオン電着塗装 (46mm 以上のサイズ)

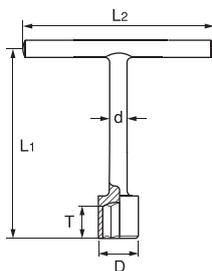

TW ロングT形ボックスレンチ

Long T-Handled Wrench

Code	mm	D mm	T mm	L ₁ mm	L ₂ mm	d mm	重量 g	箱入数	
TW0008	8	13	11	250	200	8	180	-	
TW0010	10	15.5	13	250	200	10	280	-	
TW0012	12	18	16	250	200	12	395	-	
TW0013	13	19	17	250	200	12	400	-	
TW0014	14	21	18	270	220	12	440	-	
TW0017	17	25	20	270	220	13	530	-	
TW0019	19	28	23	300	250	14	700	-	



- ・ニッケルクロムメッキ

