


## 製品詳細

### ソケット (12 角)

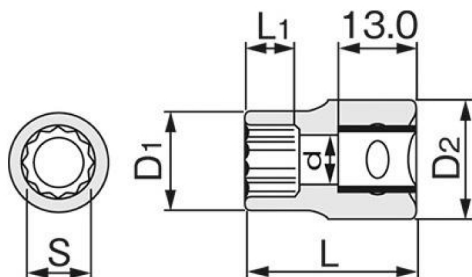

### 仕様

製品番号	二面幅寸法 (mm)S	寸法(mm) D1	寸法(mm) D2	寸法(mm) L1	寸法(mm)L	寸法(mm)d	質量(g)	EA品番
3D-08	8	11.7	17.0	6	26	7.0	20	EA618JJ-8
3D-10	10	14.7	17.0	7	26	8.0	25	EA618JJ-10
3D-11	11	15.7	17.0	8	26	9.0	30	EA618JJ-11
3D-12	12	17.0	18.0	8	26	10.0	30	EA618JJ-12
3D-13	13	18.5	18.0	9	27	10.0	35	EA618JJ-13
3D-14	14	19.5	18.0	9	27	11.0	40	EA618JJ-14
3D-15	15	21.0	18.0	10	29	11.0	50	EA618JJ-15
3D-16	16	22.0	19.0	10	29	14.0	50	EA618JJ-16
3D-17	17	23.0	19.0	11	30	14.0	70	EA618JJ-17
3D-18	18	24.5	21.0	12	32	15.0	60	EA618JJ-18
3D-19	19	26.0	21.0	13	32	16.0	70	EA618JJ-19
3D-21	21	28.0	22.5	13	32	18.0	75	EA618JJ-21
3D-22	22	30.0	23.5	14	33	18.0	95	EA618JJ-22
3D-23	23	31.0	25.5	14	33	20.0	100	EA618JJ-23
3D-24	24	32.0	25.5	15	34	20.0	110	EA618JJ-24



### ご使用上の注意

- ⚠ 注意** ・インパクトレンチなど動力工具には使用しないでください。  
 / Do not use with power tools.