




製品詳細

ソケット (6 角)

インチサイズ

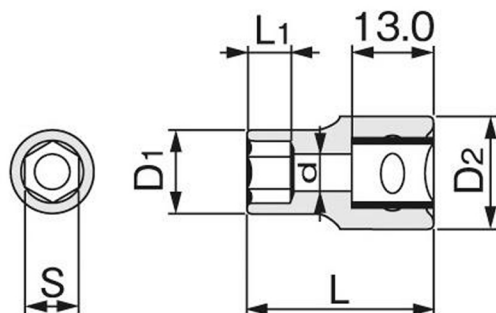

EA618JK-101



EA618JK-103

仕様

製品番号	二面幅寸法 (inch)S	寸法(mm) D1	寸法(mm) D2	寸法(mm) L1	寸法(mm) L	寸法(mm) d	質量(g)	
3SB-08	1/4	10.0	17	5	26	4.5	20	EA618JK-101
3SB-09	9/32	10.7	17	5	26	5.0	20	EA618JK-102
3SB-10	5/16	11.7	17	6	26	7.0	20	EA618JK-103
3SB-11	11/32	13.2	17	6	26	7.0	25	EA618JK-104
3SB-12	3/8	14.0	17	7	26	8.0	30	EA618JK-105
3SB-14	7/16	15.7	17	8	26	9.0	31	EA618JK-106
3SB-16	1/2	18.5	18	9	27	10.0	41	EA618JK-107
3SB-17	17/32	19.5	18	9	27	11.0	51	EA618JK-108
3SB-18	9/16	20.0	18	9	27	11.0	41	EA618JK-109
3SB-19	19/32	21.0	18	10	29	11.0	51	EA618JK-110
3SB-20	5/8	22.0	19	10	29	14.0	51	EA618JK-111
3SB-22	11/16	24.0	19	11	30	14.0	72	EA618JK-112
3SB-24	3/4	26.0	21	13	32	16.0	72	EA618JK-113

ご使用上の注意

-  **注意** ・インパクトレンチなど動力工具には使用しないでください。
／ Do not use with power tools.