

ミリサイズ

インチサイズ



3S-08L




3S-21L



3SB-08L



3SB-24L

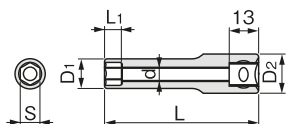

## ディープソケット (6角)

DEEP SOCKET (6pt.)

製品番号	二面幅寸法		寸法 (mm)					梱包入数		質量 (g)			
	(mm)	(inch)	D <sub>1</sub>	D <sub>2</sub>	L <sub>1</sub>	L	d	(通常)	(店飾)				
	S												
3S-5.5L	—	5.5	—	8.8	17	5	54	4	10	6	30		
3S-06L	—	6.0	—	9.3	17	5	54	4.5	10	6	30		
—	3SB-08L	6.3	1/4	10	17	5	54	4.5	10	—	40	EA618JL-121	
3S-07L	—	7.0	—	10.7	17	6	54	5	10	6	35		
—	3SB-10L	7.9	5/16	11.7	17	6	54	7	10	—	40	EA618JL-122	
3S-08L	—	8.0	—	11.7	17	6	54	7.5	10	6	35		
—	3SB-11L	8.7	11/32	13.2	17	8	54	7	10	—	50	EA618JL-123	
3S-09L	—	9.0	—	12.6	17	8	54	7	10	6	40		
—	3SB-12L	9.5	3/8	14	17	8	54	8	10	—	50	EA618JL-124	
3S-10L	—	10.0	—	14.7	17	8	54	8.5	10	6	40		
3S-11L	—	11.0	—	16	17	9	54	9.5	10	6	40		
—	3SB-14L	11.1	7/16	15.7	17	9	54	9	10	—	55	EA618JL-125	
3S-12L	—	12.0	—	18	17	9	54	10.5	10	6	50		
—	3SB-16L	12.7	1/2	18.5	18	9	54	10	10	—	70	EA618JL-126	
3S-13L	—	13.0	—	19	17	9	54	10.5	10	6	70		
—	3SB-17L	13.4	17/32	19.5	18	10	54	11	10	—	70	EA618JL-127	
3S-14L	—	14.0	—	20	18	10	54	11.4	10	6	80		
—	3SB-18L	14.2	9/16	20	18	10	54	11	10	—	75	EA618JL-128	
3S-15L	—	15.0	—	21	19	10	54	11.4	10	6	95		
—	3SB-19L	15.0	19/32	21	18	10	54	11	10	—	80	EA618JL-129	
—	3SB-20L	15.8	5/8	22	19	11	54	14	10	—	80	EA618JL-130	
3S-16L	—	16.0	—	22	20	11	54	14	10	6	110		
受注生産	—	3SB-21L	16.6	21/32	24	20	11	54	14	1	—	100	EA618JL-131
3S-17L	—	17.0	—	24	20	11	54	14.5	10	6	120		
—	3SB-22L	17.4	11/16	24	19	13	54	14	10	—	90	EA618JL-132	
3S-18L	—	18.0	—	25	21	13	54	15	10	6	145		
3S-19L	—	19.0	—	26	21	13	54	16.2	10	6	160		
—	3SB-24L	19.0	3/4	26	21	13	54	16	10	—	95	EA618JL-133	
受注生産	—	3SB-25L	19.8	25/32	27	22	18	54	16	1	—	110	EA618JL-134
受注生産	—	3SB-26L	20.6	13/16	27	22	19	54	16	1	—	105	EA618JL-135
3S-21L	—	21.0	—	29	23	15	64	18	10	6	175		
3S-22L	—	22.0	—	30	24	15	64	18	10	6	195		
受注生産	—	3SB-28L	22.2	7/8	29	24	20	64	18	1	—	120	EA618JL-136
3S-23L	—	23.0	—	31	26	15	64	20	10	6	200		
3S-24L	—	24.0	—	32	26	17	64	20	10	6	200		



※【受注生産】受注後の生産となる為、製品によって納期が異なります。納期をご確認ください。

TONE®



手工具用 ⚠ 注意 CAUTION

●インパクトレンチなど動力工具には使用しないでください。 / Do not use with power tools.