


EA618JS-8~22 (3/8")クローフットレンチ

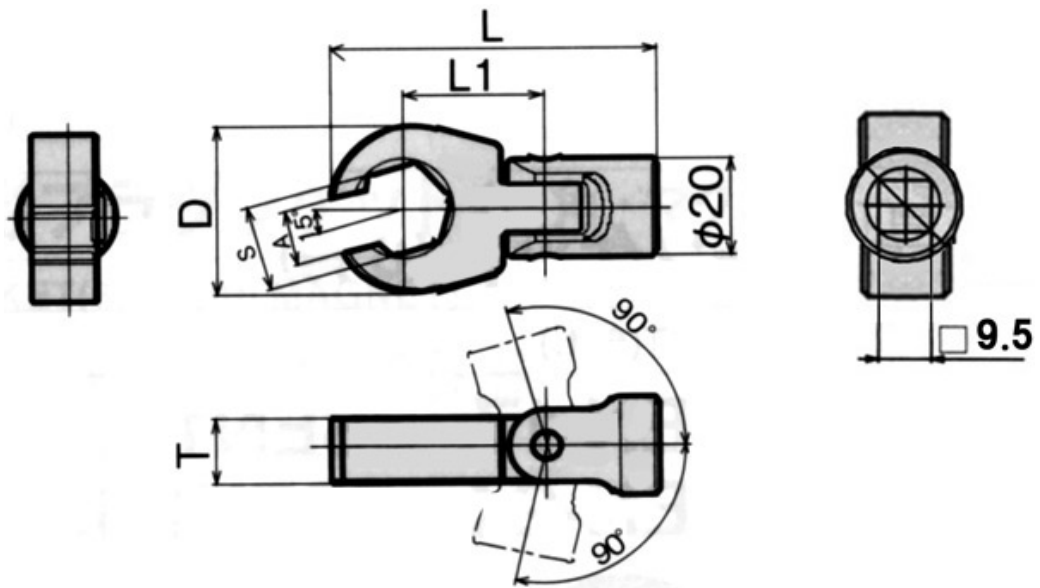

寸法

品番	S(サイズ)	D	A	T	L	L1	重量(g)
EA618JS-8	8	18	5	9.5	50.5	21	65
EA618JS-10	10	22	6.5		53	22	70
EA618JS-11	11	23	7		22.5		
EA618JS-12	12	25	8	10	55	23	75
EA618JS-13	13	26	9		58	25	80
EA618JS-14	14	28.5		11	60	26	90
EA618JS-15	15	30	10.5		61	27	95
EA618JS-16	16	32	11		63	27.5	100
EA618JS-17	17	34		13	65	28	115
EA618JS-18	18	34.5	12		66	29	
EA618JS-19	19	35	15		67	30	120
EA618JS-21	21	37		14.5	70	32	130
EA618JS-22	22	39	16		71		135

単位(mm)

- 差込角...3/8"
- 首振りタイプ
- 直接作業が出来ない複雑な箇所に使用します。

