




## 製品詳細

### ヘキサゴンソケット

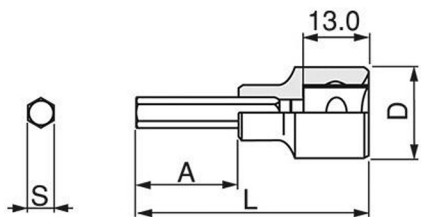

#### 仕様

製品番号	二面幅 寸法(mm)S	寸法(mm)D	寸法(mm)A	寸法(mm)L	質量(g)	EA品番
3H-2.5	2.5	17	13	40	20	EA618JT-2.5
3H-03	3	17	17	44	25	EA618JT-3
3H-04	4	17	20	47	25	EA618JT-4
3H-05	5	17	23	50	30	EA618JT-5
3H-06	6	17	25	52	35	EA618JT-6
3H-07	7	17	25	54	45	EA618JT-7
3H-08	8	19	27	56	60	EA618JT-8
3H-10	10	20	30	59	80	EA618JT-10
3H-12	12	22	33	63	100	EA618JT-12



#### ご使用上の注意



- 注意** ・インパクトレンチなど動力工具には使用しないでください。  
/ Do not use with power tools.