


製品詳細

ディープソケット (12 角)

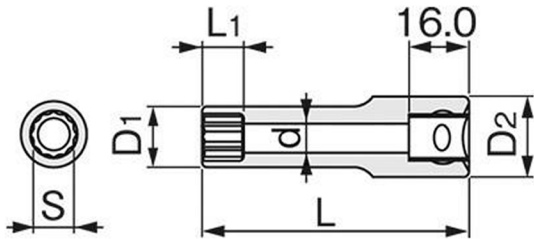

仕様

製品番号	二面幅寸法 (mm) S	寸法(mm) D1	寸法(mm) D2	寸法(mm) L1	寸法(mm) L	寸法(mm) d	質量 (g)	EA品番
4D-08L	8	12.3	22	9	83	7	95	EA618KN-8
4D-09L	9	13.5	22	9	83	7	100	EA618KN-9
4D-10L	10	15.0	22	10	83	8	110	EA618KN-10
4D-11L	11	16.2	22	10	83	9	115	EA618KN-11
4D-12L	12	17.5	22	11	83	10	125	EA618KN-12
4D-13L	13	18.8	22	11	83	11	135	EA618KN-13
4D-14L	14	20.0	22	12	83	11	145	EA618KN-14
4D-15L	15	21.0	22	12	83	11	165	EA618KN-15
4D-16L	16	23.0	22	12	83	14	145	EA618KN-16
4D-17L	17	24.0	23	16	83	14	175	EA618KN-17
4D-18L	18	25.0	23	16	83	15	165	EA618KN-18
4D-19L	19	26.0	24	18	83	17	215	EA618KN-19
4D-20L	20	28.0	26	18	83	16	225	EA618KN-20
4D-21L	21	29.0	26	18	83	18	240	EA618KN-21
4D-22L	22	30.0	26	18	83	18	270	EA618KN-22
4D-23L	23	32.0	28	18	83	20	295	EA618KN-23
4D-24L	24	33.0	28	18	83	20	330	EA618KN-24
4D-26L	26	35.0	30	20	83	22	375	EA618KN-26
4D-27L	27	36.0	30	20	83	22	395	EA618KN-27
4D-29L	29	39.0	31	21	83	22	480	EA618KN-29
4D-30L	30	40.0	34	22	83	25	490	EA618KN-30
4D-32L	32	43.0	35	22	83	25	510	EA618KN-32
4D-36L	36	48.0	38	24	83	29	540	EA618KN-36

ご使用上の注意

注意 ・ インパクトレンチなど動力工具には使用しないでください。 / Do not use with power tools.