




製品詳細

ソケット (12 角)

インチサイズ

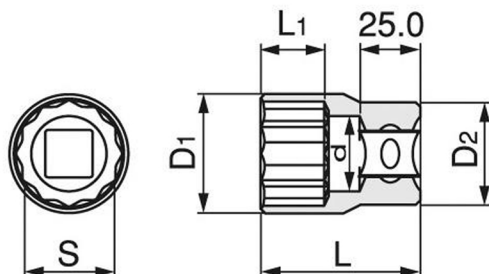

仕様

製品番号	二面幅寸法 (inch)S	寸法(mm) D1	寸法(mm) D2	寸法(mm) L1	寸法(mm) L	寸法(mm) d	質量 (g)	EA品番
6DB-24	3/4	28.0	34	14	50	16	170	EA618LL-101
6DB-26	13/16	30.0	34	15	50	18	180	EA618LL-102
6DB-28	7/8	32.0	34	15	52	18	200	EA618LL-103
6DB-30	15/16	34.0	34	17	52	20	200	EA618LL-104
6DB-32	1	36.0	34	17	52	22	200	EA618LL-105
6DB-34	1-1/16	38.0	36	19	53	22	245	EA618LL-106
6DB-36	1-1/8	40.0	37	21	56	22	270	EA618LL-107
6DB-38	1-3/16	42.0	39	21	56	25	310	EA618LL-108
6DB-40	1-1/4	44.0	40	21	56	25	345	EA618LL-109
6DB-42	1-5/16	46.0	40	21	56	25	350	EA618LL-110
6DB-44	1-3/8	48.0	40	23	58	25	400	EA618LL-111
6DB-46	1-7/16	50.0	40	24	58	30	400	EA618LL-112
6DB-48	1-1/2	52.5	43	25	60	30	465	EA618LL-113
6DB-50	1-9/16	55.5	44	25	60	30	470	EA618LL-114
6DB-52	1-5/8	55.5	44	27	63	35	480	EA618LL-115
6DB-54	1-11/16	57.0	44	27	63	35	500	EA618LL-116
6DB-56	1-3/4	60.0	45	30	65	35	550	EA618LL-117
6DB-58	1-13/16	62.0	45	30	65	35	580	EA618LL-118
6DB-60	1-7/8	65.0	46	30	67	38	650	EA618LL-119
6DB-64	2	68.0	48	32	70	38	730	EA618LL-120
6DB-68	2-1/8	74.0	50	34	76	41	925	EA618LL-121
6DB-70	2-3/16	76.0	50	36	78	41	940	EA618LL-122
6DB-72	2-1/4	80.0	52	36	80	41	1,140	EA618LL-123

ご使用上の注意

注意 ・インパクトレンチなど動力工具には使用しないでください。／ Do not use with power tools.