




製品詳細

ソケット（12 角）

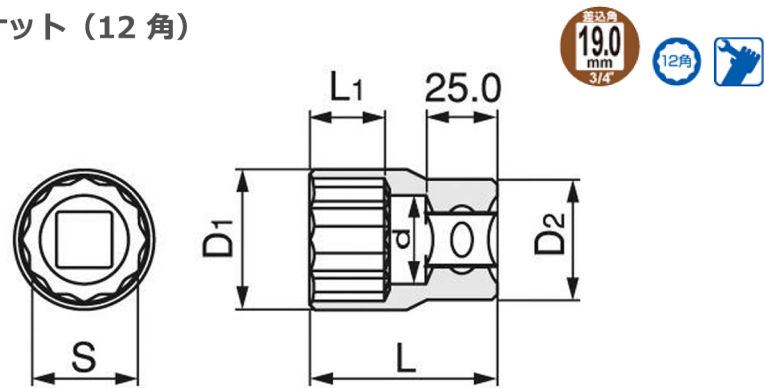

ご使用上の注意

 **注意** ・インパクトレンチなど動力工具には使用しないでください。
／ Do not use with power tools.



仕様

製品番号	二面幅寸法 (mm)S	寸法(mm) D1	寸法(mm) D2	寸法(mm) L1	寸法(mm) L	寸法(mm) d	質量(g)	EA品番
6D-17	17	26.0	34	13.0	50	14	165	EA618LL-17
6D-18	18	27.0	34	13.0	50	15	170	EA618LL-18
6D-19	19	28.0	34	14.0	50	16	170	EA618LL-19
6D-21	21	30.0	34	15.0	50	18	175	EA618LL-21
6D-22	22	32.0	34	15.0	52	18	195	EA618LL-22
6D-23	23	33.0	34	16.0	52	20	200	EA618LL-23
6D-24	24	34.0	34	17.0	52	20	200	EA618LL-24
6D-25	25	37.0	35	19.0	53	22	230	EA618LL-25
6D-26	26	37.0	35	19.0	53	22	230	EA618LL-26
6D-27	27	38.0	36	19.0	53	22	245	EA618LL-27
6D-28	28	40.0	37	21.0	56	22	280	EA618LL-28
6D-29	29	40.0	37	21.0	56	22	285	EA618LL-29
6D-30	30	42.0	39	21.0	56	25	310	EA618LL-30
6D-31	31	43.0	40	21.0	56	25	340	EA618LL-31
6D-32	32	44.0	40	21.0	56	25	345	EA618LL-32
6D-33	33	46.0	40	21.0	58	25	370	EA618LL-33
6D-34	34	47.0	40	23.0	58	25	385	EA618LL-34
6D-35	35	48.0	40	23.0	58	25	400	EA618LL-35
6D-36	36	50.0	40	24.0	58	30	420	EA618LL-36
6D-37	37	51.0	43	25.0	59	30	440	EA618LL-37
6D-38	38	52.5	43	25.0	60	30	465	EA618LL-38
6D-40	40	54.5	44	27.0	63	35	500	EA618LL-40
6D-41	41	55.5	44	27.0	63	35	525	EA618LL-41
6D-42	42	57.0	44	27.0	63	35	535	EA618LL-42
6D-46	46	62.0	45	30.0	65	35	580	EA618LL-46
6D-50	50	67.5	48	32.0	70	38	830	EA618LL-50
6D-54	54	74.0	50	34.0	76	41	925	EA618LL-54
6D-55	55	76.0	50	35.0	78	41	990	EA618LL-55
6D-58	58	80.0	52	36.0	80	41	1,130	EA618LL-58
6D-60	60	80.0	52	36.0	81	41	1,190	EA618LL-60
6D-63	63	85.0	52	45.5	83	—	1,260	EA618LL-63
6D-65	65	87.0	52	45.0	83	—	1,310	EA618LL-65