




製品詳細

ディープソケット (12角)

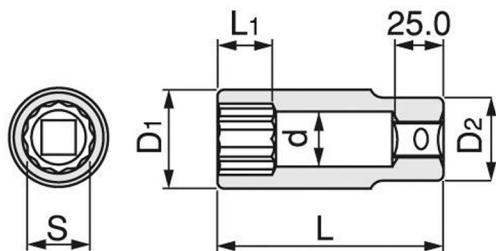

仕様

製品番号	二面幅寸法(mm)S	寸法(mm)D1	寸法(mm)D2	寸法(mm)L1	寸法(mm)L	寸法(mm)d	質量(g)	EA品番
6D-19L	19	28.0	34	14	100	16	320	EA618LM-19
6D-21L	21	30.0	34	15	100	18	340	EA618LM-21
6D-22L	22	32.0	34	15	100	18	380	EA618LM-22
6D-24L	24	34.0	34	17	100	20	400	EA618LM-24
6D-26L	26	37.0	35	19	100	22	470	EA618LM-26
6D-27L	27	38.0	36	19	100	22	500	EA618LM-27
6D-30L	30	42.0	39	21	100	25	600	EA618LM-30
6D-32L	32	44.0	40	21	100	25	670	EA618LM-32
6D-35L	35	48.0	40	23	100	25	700	EA618LM-35
6D-36L	36	50.0	40	24	100	30	800	EA618LM-36
6D-41L	41	55.5	44	27	100	35	940	EA618LM-41
6D-46L	46	62.5	45	27	100	35	1,200	EA618LM-46
6D-50L	50	67.5	48	27	100	38	1,480	EA618LM-50
6D-55L	55	76.0	50	35	100	41	1,785	EA618LM-55

ご使用上の注意



注意

・インパクトレンチなど動力工具には使用しないでください。 / Do not use with power tools.