


差込角 □12.7mm <1/2" >

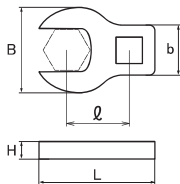

EA618TK-17
EA618TK-19
EA618TK-22
EA618TK-24
EA618TK-27
EA618TK-30
EA618TK-32
EA618TK-36

Code	mm	B mm	b mm	H mm	L mm	ℓ 有効長 mm	重量 g
VC4017	17	32	22	12	55	33	80
VC4019	19	36	22	12	57	35	90
VC4022	22	42	24	12	61	38	113
VC4024	24	46	26	12	64	38	128
VC4027	27	50	27	12	67.5	40	145
VC4030	30	54	28	12	73	43	164
VC4032	32	56	28	12	73	43	165
VC4036	36	62	30	12	77	45.5	191
VC4041	41	68	32	12	86	50	224
VC4046	46	74	32	12	91	52	254
VC4050	50	79	34	12	94	54	274
VC4055	55	84	34	12	101.5	57	314
VC4060	60	89	34	12	103.5	59	320

- ・ S50C
- ・ ニッケルクロムメッキ