
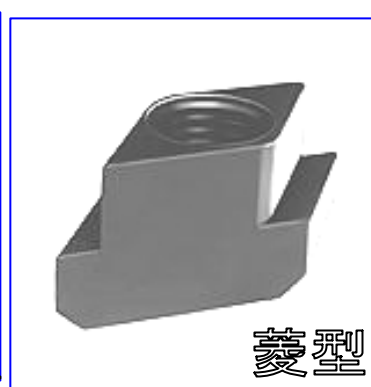



# EA637FP-FS

# Tスロットナット

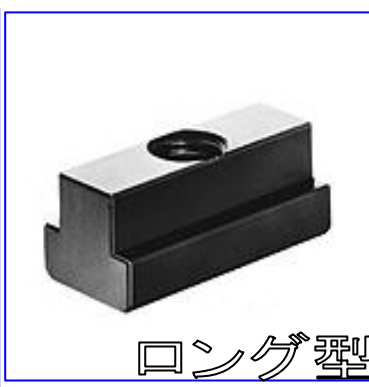


スタッドボルトのベースと一緒に御利用下さい。Tスロット差込です

品番	D x Slot	A	E	H	K	重量	
						[g]	
EA637FP-6	M 5x 6	5.7	10	8	4	4	
EA637FP-8	M 6x 8	7.7	13	10	6	9	
EA637FP-10	M 8x10	9.7	15	12	6	12	
EA637FP-12	M10x12	11.7	18	14	7	22	
EA637FP-14	M12x14	13.7	22	16	8	35	
EA637FP-18	M16x18	17.7	28	20	10	70	
EA637FP-22	M20x22	21.7	35	28	14	155	
EA637FP-28	M24x28	27.7	44	36	18	322	
EA637FP-36	M30x36	35.6	54	44	22	590	
EA637FP-42	M36x42	41.6	65	52	26	1010	
EA637FP-48	M42x48	47.6	75	60	30	1600	
EA637FP-54	M48x54	53.6	85	70	34	2300	

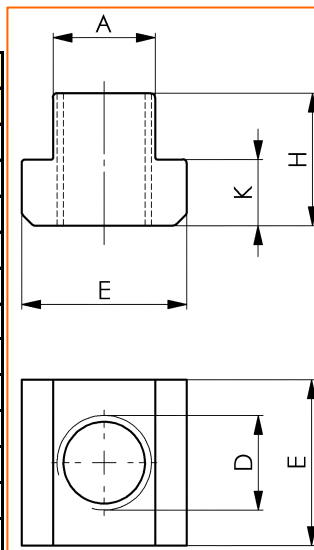

品番	D x Slot	A	E	H	K	L	重量	
							[g]	
EA637FR-6	M5x6	5.7	10	8	4	20	8	
EA637FR-8	M6x8	7.7	13	10	6	26	14	
EA637FR-10	M8x10	9.7	15	12	6	30	30	
EA637FR-12	M10x12	11.7	18	14	7	36	49	
EA637FR-14	M12x14	13.7	22	16	8	44	82	
EA637FR-16	M14x16	15.7	25	18	9	50	120	
EA637FR-18	M16x18	17.7	28	20	10	56	170	
EA637FR-20	M18x20	19.7	32	24	12	64	260	
EA637FR-22	M20x22	21.7	35	28	14	70	360	
EA637FR-28	M24x28	27.7	44	36	18	88	730	
EA637FR-36	M30x36	35.6	54	44	22	108	1390	

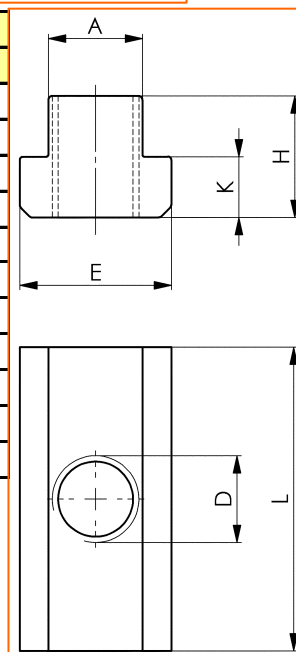

品番	D x Slot	A	E	H	K	重量	
						[g]	
EA637FS-10	M 8x10	9.7	15	12	6	11	
EA637FS-12	M10x12	11.7	18	14	7	14	
EA637FS-14	M12x14	13.7	22	16	8	22	
EA637FS-18	M16x18	17.7	28	20	10	46	
EA637FS-22	M20x22	21.7	35	28	14	98	
EA637FS-28	M24x28	27.7	44	36	18	215	
EA637FS-36	M30x36	35.6	54	44	22	430	
EA637FS-42	M36x42	41.6	65	52	26	690	

