


# EA637 GA-GH

## スタッドボルト

スロットナットやその他ナットと御利用下さい

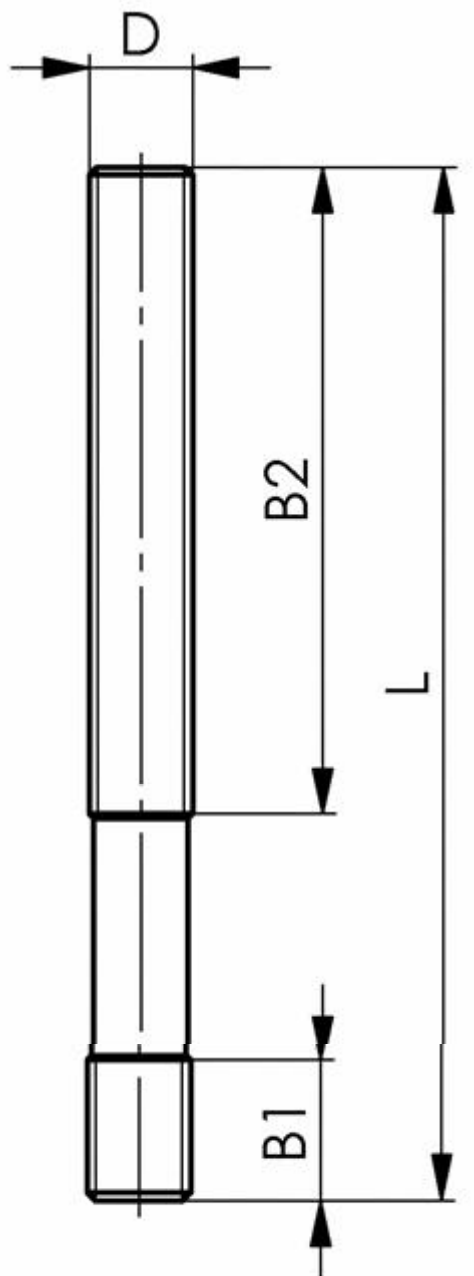

品番	D x L	B1	B2	[g]
EA637GA-50	M10x 50	13	25	25
EA637GA-80	M10x 80	13	50	40
EA637GA-100	M10x100	13	75	50
EA637GA-125	M10x125	13	75	62
EA637GA-160	M10x160	13	100	80
EA637GA-200	M10x200	13	125	100
EA637GB-50	M12x 50	15	25	37
EA637GB-63	M12x 63	15	32	45
EA637GB-80	M12x 80	15	50	55
EA637GB-100	M12x100	15	63	70
EA637GB-125	M12x125	15	75	90
EA637GB-160	M12x160	15	100	113
EA637GB-200	M12x200	15	125	140
EA637GC-63	M14x 63	17	32	80
EA637GC-80	M14x80	17	50	85
EA637GC-100	M14x100	17	63	90
EA637GC-125	M14x125	17	75	120
EA637GC-160	M14x160	17	100	150
EA637GC-200	M14x200	17	125	195
EA637GC-250	M14x250	17	160	240
EA637GD-63	M16x 63	19	32	85
EA637GD-80	M16x 80	19	50	105
EA637GD-100	M16x100	19	63	130
EA637GD-125	M16x125	19	75	160
EA637GD-160	M16x160	19	100	218
EA637GD-200	M16x200	19	125	280
EA637GD-250	M16x250	19	160	325
EA637GD-315	M16x315	19	180	425
EA637GD-500	M16x500	19	315	650
EA637GE-80	M18x 80	23	50	130
EA637GE-125	M18x125	23	75	200
EA637GE-160	M18x160	23	100	255
EA637GE-200	M18x200	23	125	320
EA637GE-250	M18x250	23	150	400
EA637GE-315	M18x315	23	180	500
EA637GF-80	M20x 80	27	32	185
EA637GF-125	M20x125	27	70	255
EA637GF-160	M20x160	27	100	330
EA637GF-200	M20x200	27	125	410
EA637GF-250	M20x250	27	160	510
EA637GF-315	M20x315	27	200	640
EA637GF-400	M20x400	27	250	815
EA637GF-500	M20x500	27	315	1020
EA637GG-100	M22x100	31	45	270
EA637GG-160	M22x160	31	100	430
EA637GG-200	M22x200	31	125	500
EA637GG-250	M22x250	31	160	670
EA637GG-315	M22x315	31	180	790
EA637GG-400	M22x400	31	250	1070
EA637GH-100	M24x100	35	45	290
EA637GH-125	M24x125	35	70	380
EA637GH-160	M24x160	35	100	470
EA637GH-200	M24x200	35	125	580
EA637GH-250	M24x250	35	160	730
EA637GH-315	M24x315	35	200	920
EA637GH-400	M24x400	35	250	1160
EA637GH-500	M24x500	35	315	1460
EA637GH-630	M24x630	35	315	1860