


NEW


ステンレス ネジ付ロングSカン



<4ミリ>

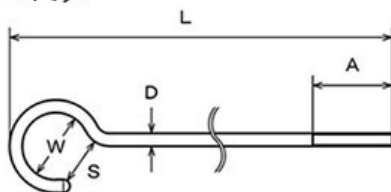

<6ミリ>

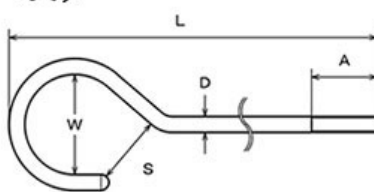

【4ミリ】

品番	D	L	W	S	A	捻径	Weight (g)	参考使用荷重	
								(kgf)	(kN)
NEW SLS-4-250	4	250	21	15	25	M-4	27	7	0.07
NEW SLS-4-500	4	500	21	15	25	M-4	52	7	0.07
NEW SLS-4-750	4	750	21	15	25	M-4	77	7	0.07
NEW SLS-4-1000	4	1000	21	15	25	M-4	102	7	0.07
NEW SLS-4-1250	4	1250	21	15	25	M-4	127	7	0.07
NEW SLS-4-1500	4	1500	21	15	25	M-4	152	7	0.07

EA63BH-1

EA638BH-2

EA638BH-3

EA638BH-4

EA638BH-5

EA638BH-6

【6ミリ】

品番	D	L	W	S	A	捻径	Weight (g)	参考使用荷重	
								(kgf)	(kN)
NEW SLS-6-250	6	250	38	25	25	M-6	69	15	0.15
NEW SLS-6-500	6	500	38	25	25	M-6	125	15	0.15
NEW SLS-6-750	6	750	38	25	25	M-6	181	15	0.15
NEW SLS-6-1000	6	1000	38	25	25	M-6	237	15	0.15
NEW SLS-6-1250	6	1250	38	25	25	M-6	293	15	0.15
NEW SLS-6-1500	6	1500	38	25	25	M-6	349	15	0.15

EA638BH-11

EA638BH-12

EA638BH-13

EA638BH-14

EA638BH-15

EA638BH-16