




Uボルト (レギュラータイプ)

"U" Bolt w/washer & nut regular type

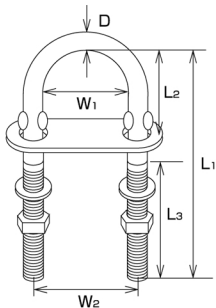

材質：ステンレス SUS304

(mm)

品番	D	L ₁	L ₂	L ₃	W ₁	W ₂	捻径	weight (g)	参考使用荷重		EA品番	コード No.
									(kgf)	(kN)		
UB-4	4	58	21	30	26	30	M-4	17	20	0.20	EA638BJ-4	442
UB-5	5	73	25	40	30	35	M-5	31	30	0.29	EA638BJ-5	443
UB-6	6	84	29	45	29	35	M-6	51	50	0.49	EA638BJ-6	444
UB-8	8	92	32	50	27	35	M-8	94	80	0.78	EA638BJ-8	445
UB-10	10	120	45	55	40	50	M-10	201	150	1.47	EA638BJ-10	446
UB-12	12	140	52	65	48	60	M-12	332	220	2.16	EA638BJ-12	447