




# アイナット

Eye Nut

〈ミリネジ〉 Metric Thread 材質：ステンレス SUS304

寸 (mm)

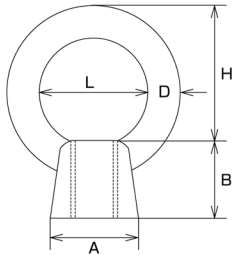

| 品番     | D   | L  | H  | B  | A  | 捻径   | weight<br>(g) | 参考使用荷重 |      | EA品番       | コード<br>No. |
|--------|-----|----|----|----|----|------|---------------|--------|------|------------|------------|
|        |     |    |    |    |    |      |               | (kgf)  | (kN) |            |            |
| IN-3M  | 3   | 9  | 12 | 6  | 9  | M-3  | 4             | 15     | 0.15 | EA638BN-3  | 821        |
| IN-4M  | 4   | 10 | 14 | 7  | 10 | M-4  | 6             | 20     | 0.20 | EA638BN-4  | 822        |
| IN-5M  | 5   | 13 | 18 | 8  | 11 | M-5  | 11            | 30     | 0.29 | EA638BN-5  | 823        |
| IN-6M  | 5.5 | 16 | 20 | 10 | 13 | M-6  | 17            | 50     | 0.49 | EA638BN-6  | 342        |
| IN-8M  | 7   | 19 | 26 | 14 | 16 | M-8  | 34            | 80     | 0.78 | EA638BN-8  | 343        |
| IN-10M | 8   | 25 | 32 | 17 | 20 | M-10 | 60            | 150    | 1.47 | EA638BN-10 | 344        |
| IN-12M | 10  | 30 | 39 | 22 | 24 | M-12 | 116           | 220    | 2.16 | EA638BN-12 | 345        |
| IN-16M | 13  | 34 | 46 | 26 | 31 | M-16 | 240           | 450    | 4.41 | EA638BN-16 | 346        |