




# アイボルト

## Eye Bolt

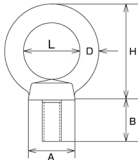

〈ミリネジ〉 Metric Thread 材質：ステンレス SUS304

(mm)

品番	D	L	H	B	A	捻径	weight (g)	参考使用荷重		コード No.	
								(kgf)	(kN)		
IB-2M	2	8	13	10	8	M-2	2	10	0.10	EA638BP-2	896
IB-3M	3	9	16	11.5	9	M-3	4	15	0.15	EA638BP-3	897
IB-4M	4	10	20	12	10	M-4	7	20	0.20	EA638BP-4	535
IB-5M	5	13	25	13	11	M-5	13	30	0.29	EA638BP-5	536
IB-6M	5.5	16	27	14	13	M-6	18	50	0.49	EA638BP-6	304
IB-8M	7	19	34	15	16	M-8	29	80	0.78	EA638BP-8	305
IB-10M	8	25	42	18	19	M-10	59	150	1.47	EA638BP-10	306
IB-12M	10	29	52	22	24	M-12	115	220	2.16	EA638BP-12	307
IB-14M	13	34	60	27	30	M-14	204	330	3.23	EA638BP-14	1001
IB-16M	13	34	61	27	30	M-16	220	450	4.41	EA638BP-16	308