


NEW

ステンレス 棒式ターンバックル (アイ&アイ)

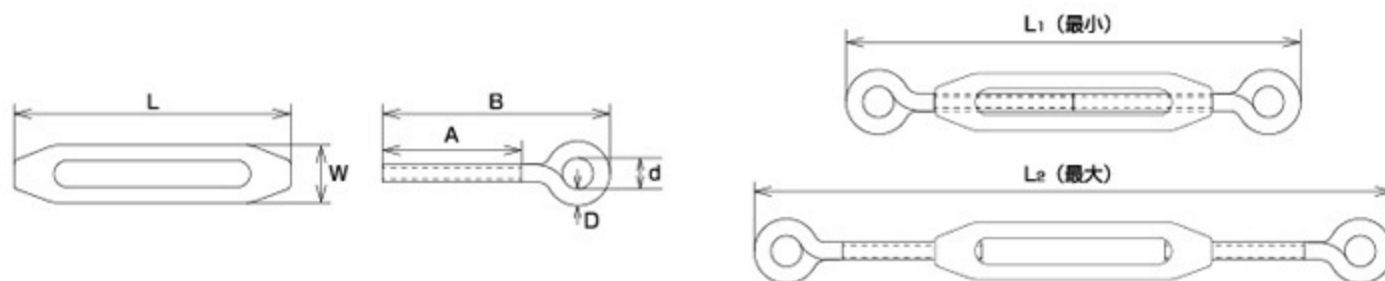

(mm)

品番		L	W	D	d	A	B	L1	L2	捻径	Weight (g)	参考使用荷重		SUS304	SUS316
												(kgf)	(kN)	定価(円)/個	定価(円)/個
EA638CD-21	TB-3E	45	8.5	2.6	7.5	22	40	80	108	M-3	10	40	0.39		-
	TB-4E	57	13	4	10	28	52	105	143	W-3/16	28	120	1.18		-
	NEW TB-4EM	57	13	3.4	10	28	50	100	138	M-4	23.5	120	1.18		-
EA638CD-22	TB-5E	70	14	4	10	35	60	120	165	W-3/16	45	130	1.27		
	NEW TB-5EM	70	14	4.2	10	35	60	120	165	M-5	48	130	1.27		-
	TB-6E	90	19	5.5	10	45	74	150	205	W-1/4	98	200	1.96		
	TB-8E	120	21	7	14	60	95	190	280	W-5/16	195	300	2.94		
	TB-9E	150	26	8.3	15	75	122	245	345	W-3/8	300	450	4.41		
	TB-12E	304	200	34	21	100	155	300	470	W-1/2	660	700	6.86		-
		316			19		160							-	
	TB-16E	250	40	14.5	25	120	183	380	540	W-5/8	1280	900	8.82		
	TB-19E	300	56	18	28	135	221	470	660	M-20	2500	1300	12.74		