


ステンレス 棒式ターンバックル (フック&フック)

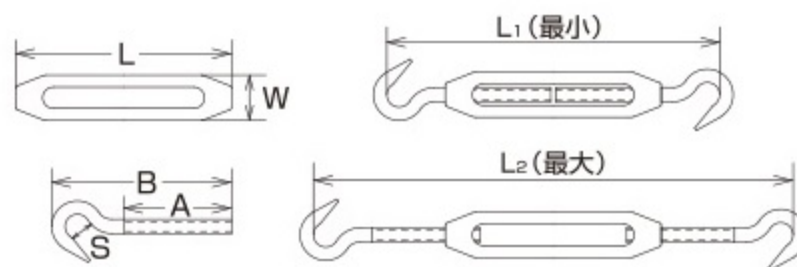

(mm)

品番	L	W	A	B	S	L1	L2	捻径	Weight (g)	参考使用荷重		SUS304	SUS316
										(kgf)	(kN)	定価(円)/個	定価(円)/個
TB-3H	45	8.5	20	37.5	4.5	74	98	M-3	10	15	0.15		-
TB-4H	57	13	28	50	6	92	128	W-3/16	27	40	0.39		-
EA638CE-21 NEW TB-4HM	57	13	30	52	6	97	135	M-4	22.5	40	0.39		-
TB-5H	70	14	35	60	7	115	160	W-3/16	41	50	0.49	-	
EA638CE-22 NEW TB-5HM	70	14	35	60	7	115	160	M-5	46	50	0.49		-
TB-6H	90	19	45	75	9	141	200	W-1/4	96	80	0.78		
TB-8H	120	21	60	100	10	180	260	W-5/16	180	120	1.18		
TB-9H	150	26	75	120	13	230	330	W-3/8	300	160	1.57		
TB-12H	200	34	100	156	17	290	440	W-1/2	640	400	3.92		
TB-16H	250	40	120	195	19	370	540	W-5/8	1250	600	5.88		
TB-19H	300	56	140	220	20	430	620	M-20	2400	700	6.86		