
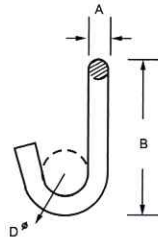


# WIRE HOOKS

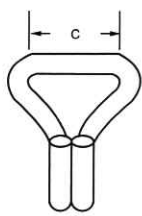

## DJ HOOK

耐荷重



(mm)

ITEM NO.	CAP. (kg)	A <sup>φ</sup>	B	C	D
DJ2506B	700	6.3	49	27	10
DJ2506A	700	6	55	27	19
DJ2507	1500	7	60	27	20
DJ2508	2000	8	80	28	20
DJ3809B	2500	9	62	36	18
DJ3809A	2500	9	85	38	16
DJ3810A	3000	10	70	38	19
DJ3810	3000	9.5	86	38	16
DJ5006	700	6	69	54	25
DJ5007	1500	7	68	51	25
DJ5008	2000	8	88	50	18
DJ5009A	3500	9.5	86	50	19
DJ5011	4000	11	105	50	25
DJ5011A	4000	11	86	50	25
DJ5012B	5000	12	85	50	25
DJ5012	5000	12	105	50	25
3" DJ7516	10000	16	143	76	20
stain DJ2507-9	650	7	60	28	20
less DJ3010-9	1500	9.5	85	38	20
steel DJ5012-9	2000	12	86	50	25

EA638FY-111



EA638FY-112

EA638FY-113

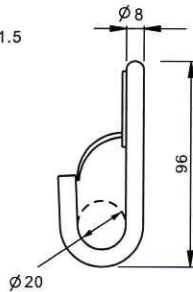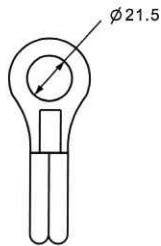

## DJS-2508



DOUBLE J HOOK WITH KEEPER  
CAP:1800kgs

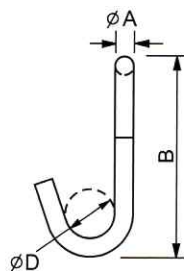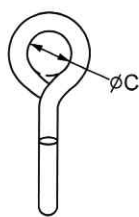

## J HOOK

(mm)

ITEM NO.	CAP. (kg)	A	B	C	D
JJ2508	300	8	108	23	17
JJ2510	545	10	100	25	25

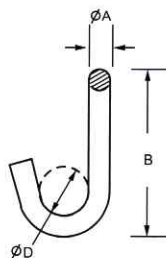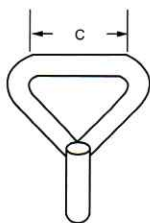

## J HOOK

(mm)

ITEM NO.	CAP. (kg)	A	B	C	D
J2508	400	8	107	25	15
J3812	3000	12	90	38	20
J5013	3500	13	153	50	23
J5014	5000	14	90	50	15
J5015	5000	15	130	50	15