


EA638H-1～-15
 ([スチール／亜鉛メッキ]クイックリング)

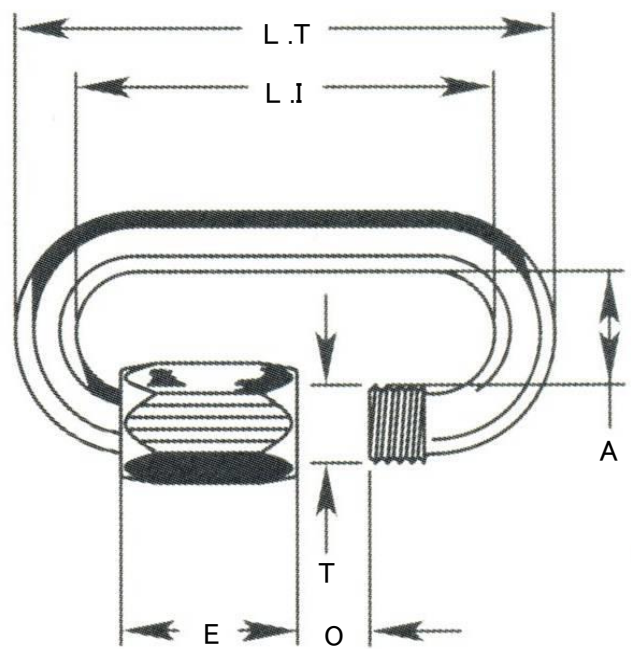

品番	線径	L.T	L.I	A	O	E	T	使用荷重	重量
	(mm)							(kg)	(g)
EA638H-1	2.5	26.0	21.0	7.0	3.5	8.0	3.5	35	3.0
EA638H-2	3.0	31.0	25.0	8.5	4.0	9.0	4.0	50	5.2
EA638H-3	3.5	36.0	29.0	10.0	5.0	11.0	5.0	100	7.9
EA638H-4	4.0	39.5	31.5	11.5	5.5	12.5	6.0	180	11.7
EA638H-5	5.0	49.5	39.5	13.0	6.5	16.0	7.0	280	20.5
EA638H-6	6.0	57.0	45.0	14.5	7.5	19.0	9.0	400	34.5
EA638H-7	7.0	66.0	52.0	16.0	8.5	21.5	10.0	550	51.0
EA638H-8	8.0	74.0	58.0	17.5	11.0	24.0	11.0	700	77.0
EA638H-9	9.0	80.0	62.0	19.0		26.0	12.0	900	102.5
EA638H-10	10.0	89.0	69.0	20.5	12.0	29.0	13.0	1100	137.0
EA638H-11	12.0	104.5	80.5	23.5	15.0	33.0	15.0	1500	232.0
EA638H-12	14.0	121.0	93.0	26.5	17.0	38.5	17.0	2200	365.0
EA638H-13	16.0	140.0	108.0	29.5	19.0	45.0	19.0	2900	562.0
EA638H-14	18.0	157.0	121.0	32.5	23.0	52.0	22.0	3500	793.2
EA638H-15	20.0	177.5	137.5	35.5	26.0	60.0	24.0	4000	1100.0

※~~EA638H-11～EA638H-15~~ は取扱中止商品です。
 ●材質・・・スチール(亜鉛メッキ)