




角頭シャックル

Square Head Pin type D-Shackle

材質：ステンレス SUS304

(mm)

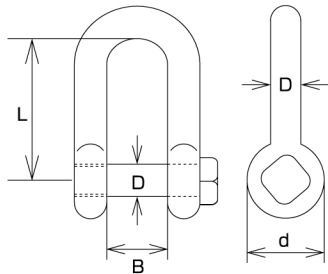

品番	D	L	B	d	捻径	weight (g)	参考使用荷重		E A 品番	コード No.
							(kgf)	(kN)		
QS-4	4	16	8	8	M-4	7	50	0.49	EA638KJ-4	666
QS-5	5	20	10	10	M-5	13	90	0.88	EA638KJ-5	571
QS-6	6	24	12	12	M-6	24	170	1.67	EA638KJ-6	572
QS-7	7	28	14	14	W-5/16	39	200	1.96	EA638KJ-7	230
QS-8	8	32	17	16	W-5/16	57	250	2.45	EA638KJ-8	231
QS-9	9	36	18	18	W-3/8	78	300	2.94	EA638KJ-9	232
QS-10	10	40	20	20	W-3/8	115	350	3.43	EA638KJ-10	233
QS-12	12	48	24	24	W-1/2	190	420	4.12	EA638KJ-12	234
QS-13	13	52	26	26	W-1/2	240	500	4.90	EA638KJ-13	235
QS-16	16	64	32	32	W-5/8	460	800	7.84	EA638KJ-16	236
QS-19	19	76	38	38	W-3/4	755	1000	9.80	EA638KJ-19	237