
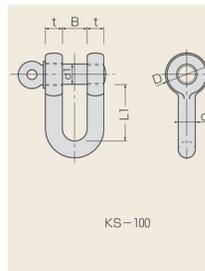
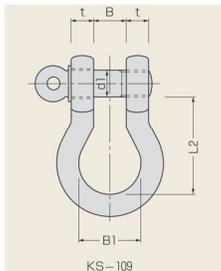
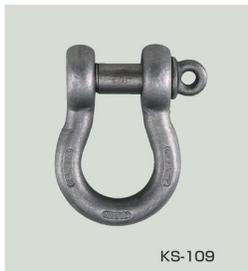
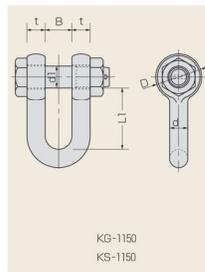
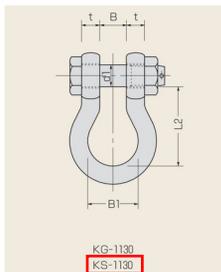


US 型強カシャックル

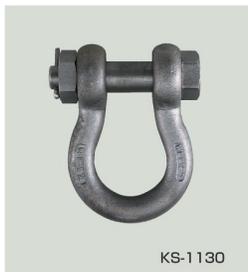

■ ボルト・ナット型 (KS-1130/KS-1150) + 100ton 130ton 150tonは丸頭形状に取手ハンドル付。

(単位: mm)

規格サイズコード		呼び	使用荷重		d(t)	d1	B	B1	L1	L2	D	重量 (kg)	
1130	1150		t	kN								1130	1150
BBW040	SBW040	1/2	2 (19.6)	13	16	21	33.5	42	48	30	0.395	0.35	
BBW050	SBW050	5/8	3 1/4 (31.85)	16	19	27	43	51	61	40	0.726	0.71	
BBW060	SBW060	3/4	4 3/4 (46.55)	19	22	32	51	61	72	48	1.2	1.1	
BBW070	SBW070	7/8	6 1/2 (63.7)	22	25	37	58	72	85	54	1.8	1.66	
BBW100	SBW100	1	8 1/2 (83.3)	25	28	43	69	81	96	60	2.5	2.35	
BBW110	SBW110	1 1/8	9 1/2 (93.1)	28	32	46	74	91	108	67	3.56	3.4	
BBW120	SBW120	1 1/4	12 (117.6)	32	36	52	83	100	119	76	5.1	4.8	
BBW130	SBW130	1 1/2	13 1/2 (132.3)	36	38	58	92	113	134	84	7	6.65	
BBW140	SBW140	1 3/4	17 (166.6)	38	42	61	99	124	146	92	8.6	8.1	
BBW160	SBW160	2	25 (245)	46	50	73	127	146	178	110	14	14	
BBW200	SBW200	2 1/2	35 (343)	50	57	83	146	172	197	127	22	21	
BBW240	SBW240	3	50 (490)	65	70	105	184	204	267	153	43	38	
BBW300	SBW300	3 1/2	75 (735)	75	83	127	200	216	330	165	66	56	
BBW340	SBW340	4	+100 (980)	90	96	134	228	266	372	203	115	100	
BBW400	SBW400	4 1/2	+130 (1274)	100	108	140	254	305	418	228	163	121	
BBW430	SBW430	5	+150 (1470)	110	120	165	275	351	464	246	238	204	

*安全率5倍以上

■ ねじ込型 (KS-109/KS-100)

(単位: mm)

規格サイズコード		呼び	使用荷重		d(t)	d1	B	B1	L1	L2	D	重量 (kg)	
109	100		t	kN								109	100
BAW040	SAW040	1/2	2 (19.6)	13	16	21	33.5	42	48	30	0.34	0.3	
BAW050	SAW050	5/8	3 1/4 (31.85)	16	19	27	43	51	61	40	0.65	0.57	
BAW060	SAW060	3/4	4 3/4 (46.55)	19	22	32	51	61	72	48	1.1	1	
BAW070	SAW070	7/8	6 1/2 (63.7)	22	25	37	58	72	85	54	1.6	1.45	
BAW100	SAW100	1	8 1/2 (83.3)	25	28	43	69	81	96	60	2.3	2.1	
BAW110	SAW110	1 1/8	9 1/2 (93.1)	28	32	46	74	91	108	67	3.3	2.9	
BAW120	SAW120	1 1/4	12 (117.6)	32	36	52	83	100	119	76	4.65	4.1	
BAW130	SAW130	1 1/2	13 1/2 (132.3)	36	38	58	92	113	134	84	6.2	5.3	
BAW140	SAW140	1 3/4	17 (166.6)	38	42	61	99	124	146	92	7.7	7.01	
BAW160	SAW160	2	25 (245)	46	50	73	127	146	178	110	13	12	
BAW200	SAW200	2 1/2	35 (343)	50	57	83	146	172	197	127	19.5	18	
BAW240	SAW240	3	50 (490)	65	70	105	184	204	267	153	40	35	

*安全率5倍以上

- EA638NL-1
- EA638NL-2
- EA638NL-3
- EA638NL-4
- EA638NL-5
- EA638NL-6
- EA638NL-7
- EA638NL-8
- EA638NL-9