
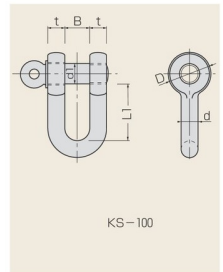
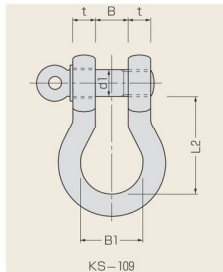
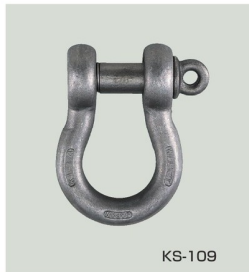
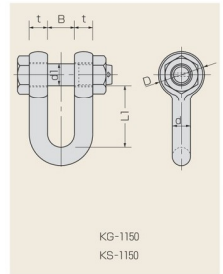


US 型強カシャックル

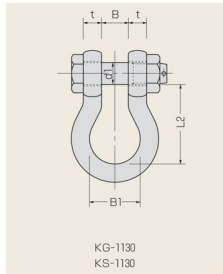

■ ボルト・ナット型 (KS-1130/KS-1150) + 100ton 130ton 150tonは丸頭形状に取手ハンドル付。

(単位: mm)

規格サイズコード		呼び	使用荷重		d(t)	d1	B	B1	L1	L2	D	重量 (kg)	
1130	1150		t	kN								1130	1150
BBW040	SBW040	1/2	2	(19.6)	13	16	21	33.5	42	48	30	0.395	0.35
BBW050	SBW050	5/8	3 1/4	(31.85)	16	19	27	43	51	61	40	0.726	0.71
BBW060	SBW060	3/4	4 3/4	(46.55)	19	22	32	51	61	72	48	1.2	1.1
BBW070	SBW070	7/8	6 1/2	(63.7)	22	25	37	58	72	85	54	1.8	1.66
BBW100	SBW100	1	8 1/2	(83.3)	25	28	43	69	81	96	60	2.5	2.35
BBW110	SBW110	1 1/8	9 1/2	(93.1)	28	32	46	74	91	108	67	3.56	3.4
BBW120	SBW120	1 1/4	12	(117.6)	32	36	52	83	100	119	76	5.1	4.8
BBW130	SBW130	1 3/8	13 1/2	(132.3)	36	38	58	92	113	134	84	7	6.65
BBW140	SBW140	1 1/2	17	(166.6)	38	42	61	99	124	146	92	8.6	8.1
BBW160	SBW160	1 3/4	25	(245)	46	50	73	127	146	178	110	14	14
BBW200	SBW200	2	35	(343)	50	57	83	146	172	197	127	22	21
BBW240	SBW240	2 1/2	50	(490)	65	70	105	184	204	267	153	43	38
BBW300	SBW300	3	75	(735)	75	83	127	200	216	330	165	66	56
BBW340	SBW340	3 1/2	+100	(980)	90	96	134	228	266	372	203	115	100
BBW400	SBW400	4	+130	(1274)	100	108	140	254	305	418	228	163	121
BBW430	SBW430	4 3/8	+150	(1470)	110	120	165	275	351	464	246	238	204

*安全率5倍以上

■ ねじ込型 (KS-109/KS-100)

(単位: mm)

規格サイズコード		呼び	使用荷重		d(t)	d1	B	B1	L1	L2	D	重量 (kg)	
109	100		t	kN								109	100
BAW040	SAW040	1/2	2	(19.6)	13	16	21	33.5	42	48	30	0.34	0.3
BAW050	SAW050	5/8	3 1/4	(31.85)	16	19	27	43	51	61	40	0.65	0.57
BAW060	SAW060	3/4	4 3/4	(46.55)	19	22	32	51	61	72	48	1.1	1
BAW070	SAW070	7/8	6 1/2	(63.7)	22	25	37	58	72	85	54	1.6	1.45
BAW100	SAW100	1	8 1/2	(83.3)	25	28	43	69	81	96	60	2.3	2.1
BAW110	SAW110	1 1/8	9 1/2	(93.1)	28	32	46	74	91	108	67	3.3	2.9
BAW120	SAW120	1 1/4	12	(117.6)	32	36	52	83	100	119	76	4.65	4.1
BAW130	SAW130	1 3/8	13 1/2	(132.3)	36	38	58	92	113	134	84	6.2	5.3
BAW140	SAW140	1 1/2	17	(166.6)	38	42	61	99	124	146	92	7.7	7.01
BAW160	SAW160	1 3/4	25	(245)	46	50	73	127	146	178	110	13	12
BAW200	SAW200	2	35	(343)	50	57	83	146	172	197	127	19.5	18
BAW240	SAW240	2 1/2	50	(490)	65	70	105	184	204	267	153	40	35

*安全率5倍以上

- EA638NP-1
- EA638NP-2
- EA638NP-3
- EA638NP-4
- EA638NP-5
- EA638NP-6
- EA638NP-7
- EA638NP-8
- EA638NP-9