


SIN シャックル (JIS 型沈シャックル)

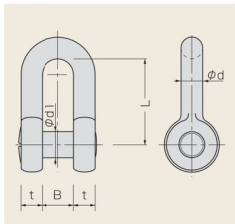

規格サイズ コード	呼び t・d	使用荷重		B(mm) (口幅)	L(mm) (長さ)	d1(mm) (ピン径)	重量 (kg)
		tf	kN				
A016	16	1.5	(14.7)	26	64	19	0.58
A018	18	2	(19.6)	29	72	21	0.82
A020	20	2.5	(24.5)	31	80	24	1.15
A022	22	3	(29.4)	34	88	26	1.53
A024	24	3.6	(35.28)	39	96	30	2.08
A026	26	4.2	(41.16)	41	104	32	2.61
A028	28	4.8	(47.04)	43	112	34	3.24
A030	30	5.4	(52.92)	45	120	36	3.91
A032	32	6.2	(60.76)	48	128	38	4.75
A034	34	7	(68.6)	50	136	40	5.67
A036	36	8	(78.4)	54	144	42	6.74
A038	38	9	(88.2)	57	152	46	7.97
A040	40	10	(98)	60	160	48	9.2

EA638NR-1

EA638NR-2

EA638NR-3

EA638NR-4

EA638NR-5

EA638NR-6

EA638NR-7

EA638NR-8

EA638NR-9

EA638NR-10

EA638NR-11

EA638NR-12

EA638NR-13