


アイボルト



仕 様	
材 質	鉄 (SS400)
表面処理	鉄 (生地)

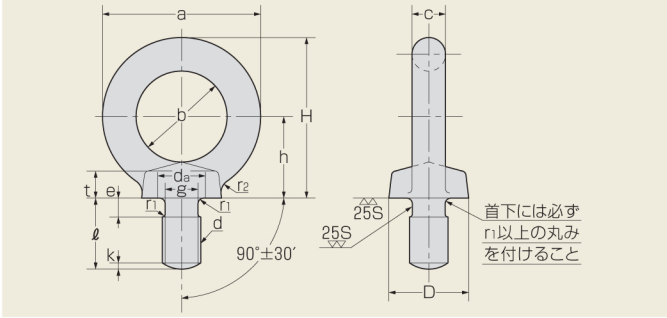

■アイボルト寸法表 寸法はJIS B 1168-1994による

単位:mm

ねじの呼び (d)		a	b	c	D	t	h	H (参考)	ℓ	e	g (最小)	r ₁ (最小)	d _a (最大)	r ₂ (約)	k (約)	使用荷重 垂直吊りまたは2個で45°吊り		重量 (kg) (約)
																Mねじ	Wねじ	
																kN (kgf)	kN (kgf)	
(6)	(1/4)	26	16	5.8	13.5	6	14	27	14	2	4.5	0.8	7.1	2	1	0.588 (60)		0.016
8	5/16	32.6	20	6.3	16	5	17	33.3	15	3	6	1	9.2	4	1.2	0.785 (80)		0.03
10	3/8	41	25	8	20	7	21	41.5	18	4	7.7	1.2	11.2	4	1.5	1.47 (150)	1.37 (140)	0.06
12	1/2	50	30	10	25	9	26	51	22	5	9.4	1.4	14.2	6	2	2.16 (220)	2.16 (220)	0.12
16	5/8	60	35	12.5	30	11	30	60	27	5	13	1.6	18.2	6	2	4.41 (450)	3.92 (400)	0.22
20	3/4	72	40	16	35	13	35	71	30	6	16.4	2	22.4	8	2.5	6.18 (630)	5.88 (600)	0.39
(22)	(7/8)	80	44	19	40	16.5	43	84	35	7	18.5	2.3	24.4	10	2.5	7.74 (790)	7.84 (800)	0.56
24	1"	90	50	20	45	18	45	90	38	8	19.6	2.5	26.4	12	3	9.32 (950)	9.32 (950)	0.80
30	1 1/4	110	60	25	60	22	55	110	45	8	25	3	33.4	15	3.5	14.7 (1500)	14.7 (1500)	1.56
36	1 1/2	133	70	31.5	70	26	65	131.5	55	10	30.3	3	39.4	18	4	22.6 (2300)	22.6 (2300)	2.90
42	1 3/4	151	80	35.5	80	30	75	150.5	65	12	35.6	3.5	45.6	20	4.5	33.3 (3400)	33.3 (3400)	4.40
48	2"	170	90	40	90	35	85	170	70	12	41	4	52.6	22	5	44.1 (4500)	44.1 (4500)	6.10
64	2 1/2	210	110	50	110	42	105	210	90	14	55.7	5	71	25	6	88.3 (9000)	88.3 (9000)	11.50
80	3"	266	130	63	130	50	130	263	105	14	71	5	87	35	6	147 (15000)	127 (13000)	26.25
90		302	150	74	150	55	150	301	120	14	81	5	97	35	6	177 (18000)	167 (17000)	46.00
100	4"	340	170	80	170	60	165	335	130	14	91	5	108	40	6	196 (20000)	196 (20000)	49.00

※Wねじの寸法および使用荷重については、JIS B 1168-1960～1966に準じます。 ※ () は参考値です。

■(Mねじ)

呼び (d)	生地	
	規格サイズコード	EA品番
(6)	AM06	EA638SN-6
8	AM08	EA638SN-8
10	AM10	EA638SN-10
12	AM12	EA638SN-12
16	AM16	EA638SN-16
20	AM20	EA638SN-20
(22)	AM22	EA638SN-22
24	AM24	EA638SN-24
30	AM30	EA638SN-30
36	AM36	EA638SN-36
42	AM42	EA638SN-42
48	AM48	EA638SN-48
64	AM64	
80	AM80	
90	AM90	
100	AM100	

