


# EA684B-2~-20 片目片口スパナ

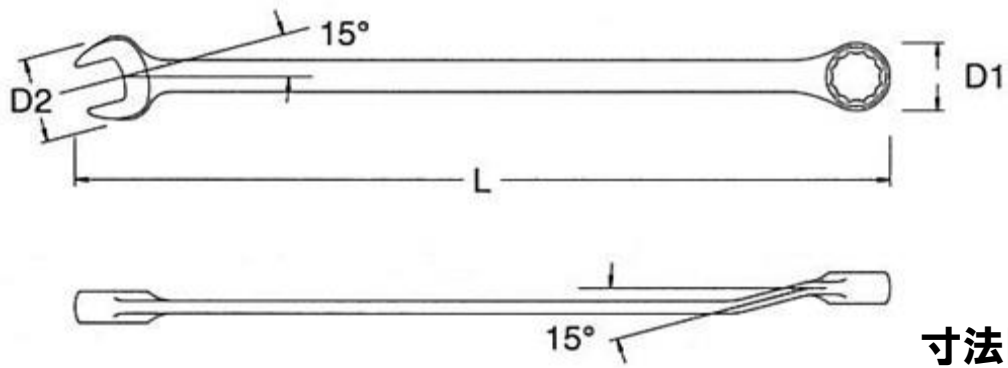

寸法図

品番	サイズ	L(全長)	D1	D2	重量(g)
EA684B-2	1/4"	126	10.7	13.5	17
EA684B-2.5	5/16"	139	13.9	16.7	28
EA684B-3	3/8"	151	15.3	20.9	40
EA684B-3.5	7/16"	166	17.7	23.0	50
EA684B-4	1/2"	178	20.1	27.2	58
EA684B-4.5	9/16"	191	21.5	29.3	78
EA684B-5	5/8"	209	24.5	33.4	125
EA684B-5.5	11/16"	226	26.7	35.5	133
EA684B-6	3/4"	248	28.5	39.7	185
EA684B-6.5	13/16"	270	30.6	43.9	212
EA684B-7	7/8"	293	32.3	46.0	277
EA684B-7.5	15/16"	315	34.1	50.1	338
EA684B-8	1"	334	36.0	52.2	395
EA684B-10.5	1-1/16"	359	38.8	56.4	513
EA684B-11	1-1/8"	403	42.8	62.7	678
EA684B-12	1-1/4"	430	46.0	65.6	826
EA684B-12.5	1-5/16"	475	48.0	68.0	1080
<del>EA684B-13</del>	1-3/8"				1056
EA684B-13.5	1-7/16"	500	55.0	77.0	1475
<del>EA684B-14</del>	1-1/2"				1540
<del>EA684B-15</del>	1-5/8"				2000
EA684B-16	1-3/4"	580	60.0	84.0	2480
EA684B-17	1-7/8"				600
EA684B-20	2"	650	72.0	97.0	2960

※ ~~EA684B-13~~ は取扱中止商品です。

単位(mm)

- 材質…クロムバナジウム鋼
- 15° タイプ



- 12.5~-20のサイズの表面は梨地仕上げとなっています。