

ANGLE PLATE




基本情報

Basic information

- 鋳抜き孔を利用した固定が可能です。
- 直角に仕上げているので簡易的な横中グリ作業、旋盤作業に使用できます。

材質 FC250

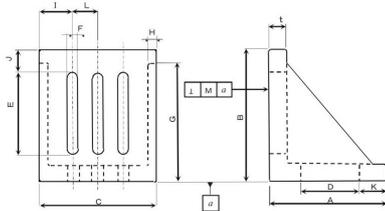

●OS-167 精度・寸法表 Accuracy & dimensions OS-167

品番 Code No.	A級 Class A	長(A)×高(B)×厚(D) [Lgth. Hght. Wdth.]	寸法 Size (mm)													公差 (mm)		重量 Weight (kg)
			t	D	E	F	G	H	I	J	K	L	±0.005/0.010/0.020	±0.005/0.010/0.020				
167-75K	167-75A	75 × 100 × 75	15	25	48	12	80	8	25	15	15	25	0.05	0.015	2	1.4	EA718AB-1A	
167-100K	167-100A	100 × 128 × 100	18	34	90	12	112.5	8	24	15	15	26	0.05	0.016	3	2.4	EA718AB-2A	
167-125K	167-125A	125 × 150 × 125	14	35	100	14	135	10	35.5	20	23	27	0.05	0.018	3	3.7	EA718AB-3A	
167-150K	167-150A	150 × 175 × 150	22	75	108	12	157.5	10	42	33	35	33	0.1	0.019	3	7.3	EA718AB-4A	
167-175K	167-175A	175 × 200 × 175	21	120	150	16	180	10	33.5	25	25	36	0.1	0.02	4	8.5	EA718AB-5A	
167-200K	167-200A	200 × 250 × 200	25	140	195	20	225	15	45	25	25	38	0.1	0.023	4	13.3	EA718AB-6A	
167-250K	167-250A	250 × 300 × 250	32	180	230	24	270	15	45.5	30	30	63	0.1	0.025	4	26		
167-300K	167-300A	300 × 350 × 300	34	185	230	20	315	15	55	45	35	47.5	0.1	0.026	5	44.8		
167-350K	167-350A	350 × 400 × 350	35	225	285	24	325	20	52	50	51	51	0.1	0.03	5	49.2		
167-400K	167-400A	400 × 450 × 400	45	248	300	27	250	20	60	60	60	60	0.15	0.033	5	68.4		
167-450K	167-450A	450 × 500 × 450	50	268	338	27	250	25	75	50	50	75	0.15	0.036	5	120		
167-500K	167-500A	500 × 550 × 500	57	330(28)	350(28)	24	470	25	115	75	75	90	0.15	0.038	4×2	145		

①は標準的な  
寸法です。