


Adjustable Angle Block 0-60°

PAB

Manufactured from finely selected tool steel, fully hardened 50-55 HRC & precision ground

Fully adjustable from 0-60° and can be set at any desired position by locking of the hex screw located in the base

Useful for most drilling, milling and set up jobs where a particular angle to a reference face is required

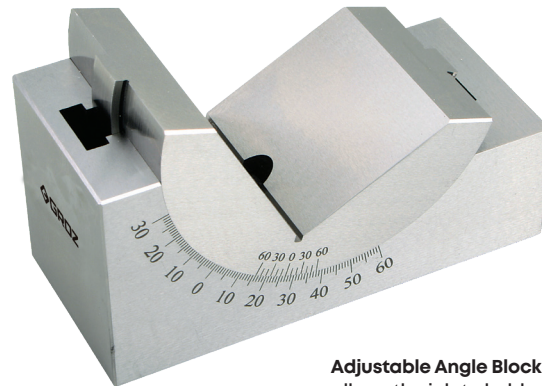

SPECIFICATIONS

SQUARENESS	0.0004"	10 μ
ANGLE ACCURACY	±10'	

ORDERING INFORMATION

CAT NR.	ORD NR.	BLOCK LENGTH		BLOCK WIDTH		BLOCK HEIGHT		WIDTH OF VEE		BOX QTY.
		(INCH)	(MM)	(INCH)	(MM)	(INCH)	(MM)	(INCH)	(MM)	
* PAB/01/A	02100	3-3/4	95	1-3/4	45	2	50	1-29/32	48.5	15
PAB/02/A	02101	3-3/4	95	1-3/16	30	2	50	1-29/32	48.5	15
PAB/03/A	02103	3	75	1	25	1-11/32	34	1-5/32	29.5	15

* Best Seller

Adjustable Angle Block
allows the job to held at any angle 0-60° for angular machining jobs

