


EA723MF-1～-12 アジャスタブルトルクレンチ

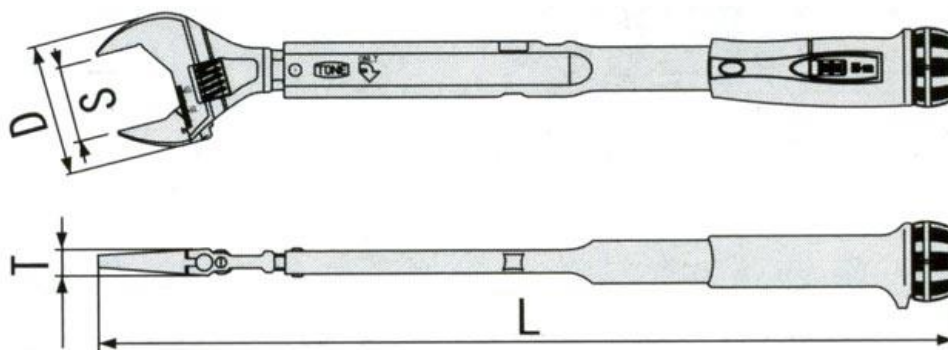

(mm)

品番	トルク範囲 (Nm)	1目盛	D	S	T	L	重量(g)
EA723MF-1	3~15	0.2	49.3	10~27	9.9	289	320
EA723MF-2	5~25	0.2	49.3	10~27	9.9	330	460
EA723MF-4	10~50	0.5	49.3	10~27	9.9	330	460
EA723MF-6	15~60	0.5	49.3	10~27	9.9	330	460
EA723MF-7	20~100	1	66.8	17~38	13.3	420	740
EA723MF-9	25~115	1	66.8	17~38	13.3	420	740
EA723MF-10	50~150	1	66.8	17~38	13.3	483	820
EA723MF-12	40~200	2	85	27~48	16	570	1510

MF-6、-9は新冷媒対応



- トルク設定値がひと目でわかる数字表示!!

