

インサイドマイクロメータ

CLIPPER-TYPE INSIDE MICROMETERS

0点調整用の国内自社工場製リングゲージを標準装備！すぐに使用できます。




MC304-301



MC304-501




MC304-751

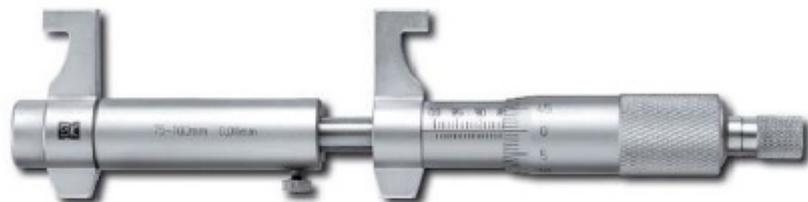


MC304-1001



寸法図

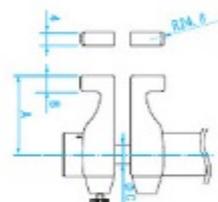

※ MC304-501 ~ 1001
測定子拡大図

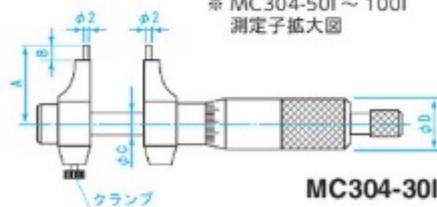

MC304-301

■ **用途** • 内側寸法の測定

■ **材質** • スピンドル：高炭素クロム軸受鋼

■ **特長** • 基準リングゲージ付
MC304-30I：φ 5
MC304-50I：φ 25
MC304-75I：φ 50
MC304-100I：φ 75
• 定圧装置付
• 測定面は超硬チップ付

単位：mm

品番	A	B	C	D
MC304-30I	28	5	8	18
MC304-50I	28	5	8	18
MC304-75I	28	5	8	18
MC304-100I	28	5	8	18

商品コード	品番	測定範囲 (mm)	最小読取値 (mm)	最大許容誤差 (μm)	質量
151230	MC304-30I	5 ~ 30	0.01	5	140g
151231	MC304-50I	25 ~ 50	0.01	6	150g
 151232	MC304-75I	50 ~ 75	0.01	7	160g
 151233	MC304-100I	75 ~ 100	0.01	8	190g

EA725EJ-21
EA725EJ-22