

## 105050

- Automatische Reset-Funktion der Max.- und Min. - Temperatur
- Automatische Löschung der gespeicherten Max.-Temperatur um 8.00 Uhr
- Automatische Löschung der gespeicherten Min.-Temperatur um 20.00 Uhr

### Einstellung der Uhrzeit:

- Entfernen Sie das Display durch seitliches Schieben aus der Halterung.
- Legen Sie die Batterie ein.
- Die Anzeige "H" und "M" blinkt.
- Drücken Sie die "Set" - Taste, "AM 12" blinkt.
- Drücken Sie die "UP" - Taste um die Stunden einzustellen. Bestätigen Sie durch Drücken der "Set" - Taste. "00" blinkt.
- Drücken Sie die "UP" - Taste um die Minuten einzustellen. Bestätigen Sie durch Drücken der "Set" - Taste.
- Beenden Sie die Einstellung durch Drücken der "MODE" - Taste.

## 105050

- « Reset » Fonction automatique de la température maxima et minima.
- Effacement automatique de la température maxima à 8 heures.
- Effacement automatique de la température minima à 20 heures.

### Réglage de l'horloge :

- Pour ôter le « Display », poussez le sur le côté.
- Insérer les piles.
- L'indicateur « H » et « M » clignote.
- Appuyer sur la touche « SET » et l'indication « AM 12 » clignote.
- Pour régler l'heure, appuyer sur la touche « UP ». Confirmer l'heure en appuyant sur la touche « SET ». L'indication « OO » clignote.
- Appuyer sur la touche « UP » pour régler les minutes. Confirmer en appuyant sur la touche « SET ».
- Pour finaliser le réglage de l'horloge, appuyer sur la touche « MODE ».

This unit is programmed with daily Max & Min reset function. Local time must be set with the unit before using. Reset function will be automatically activated at 08:00 am for max temp and 08:00 pm for min temp daily.


#### **Time setting:**

- Withdraw the plastic case from the hanging case by pushing the plastic case either sideward as below.
- Open the battery door by unfastening the screw with the aid of screwdriver.
- Put in battery (this action equals to reset function) Battery type: AAA battery 1.5 V x1 pc.
- All segment shown on display for 2 seconds.
- Time Mode shown on display (AM 12 default)  
(H & M flashing simultaneously) H = Hours / M = Minutes
- Press "SET" button, "AM 12" flashing, and Press "UP" button to adjust hour
- Press "SET" to confirm and "00" flashing,
- Press "UP" button to adjust minute and Press "SET" button to confirm
- Press "MODE" button to return to thermometer.

**°C/°F button:** for Celsius and Fahrenheit conversion.

#### **Replacement of Battery:**


After replacement of battery, please follow the order illustrated to fix rubber ring into a groove to keep the item waterproof.

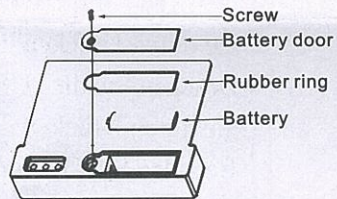

#### **Mounting of hanging case (not for -SC versions)**

Please read all the followings carefully before any action.

- Double adhesive tapes are already attached on the hanging case in factory.
- Choose and clean the location of mounting.  
Please make sure that there is 15 cm on the side(s) which the thermometer will be slide in.
- Remove the PE liner on the adhesive tapes.
- Fix the hanging case on the location.
- Slide in the thermometer. Make sure that it faces to the correct side.

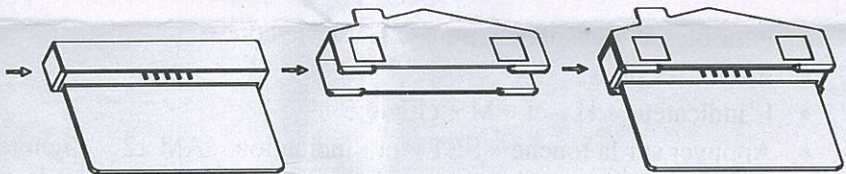

Thrust the plastic case through the guide way of hanging case to assemble the product. Do not push LCD to assemble the product. This may cause damage of product.

**Caution:** LCD is made of glass and it is fragile. It can be broken when it falls on the ground.

**Remarks:** The adhesive tapes cannot be used again after removal.