

Worklight

Wireless Charging

LED-375



Integrated

- a. 10W COB worklight
- b. 2W SMD top torch

Light Output

High quality light output in multiple modes

	LUMEN	RUN TIME	LUMEN	RUN TIME	LUMEN	RUN TIME
INTENSITY	HIGH		MEDIUM		LOW	
WORKLIGHT	1000	1.5 hours	500	2.5 hours	250	5 hours
TOP TORCH	120 lumen with a run time of 8 hours					

Sturdy Construction

- a. **IP 65 Rated**
Protection against dust and effects of pressure jets from any direction
- b. **IK 07 Rated**
Impact-proof with ABS body

Sturdy polycarbonate lens to withstand the toughest of jobs site conditions

Nylon hook with 360° rotating action for convenient placement of light

Swivelling Magnetic Base


The base can rotate upto 180° to adjust to the required angle

Strong magnet on the base makes it easy to mount onto any metallic surface for hands free use.

Dual Battery Charging Options

1. Wireless charging using induction charging technology
2. Can also be charged using micro USB cable provided with the light

POWER SOURCE

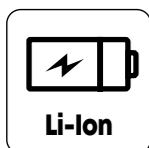

3.7V 3350 mAh



CE
RoHS
IP65
IK07

BATTERY CHARGING OPTIONS



Wireless (Induction) Charging
Can be mounted on metallic surfaces or hung on the wall using nails or hooks



With Micro USB Cable
USB charging port with LED charge indicators



Swivelling Magnetic Base
The base can rotate upto 180° to adjust to the required angle

ORDERING INFORMATION

CAT NR.	ORD NR.	SIZE (LxWxD)		BOX QTY.
		(INCH)	(MM)	
LED/375	55085	9 x 2 x 1-5/8	230 x 59 x 41.5	12



SCAN TO WATCH